


MATERIAL

Cast stainless steel, sandblasted matte finish.

STANDARD EXECUTION

Threaded pass-through hole.

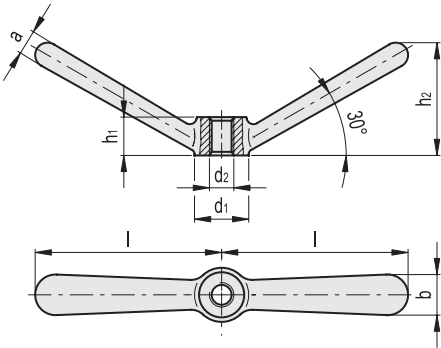

Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
16	0.63
20	0.79
25	0.98
32	1.26
40	1.57

Code	Description	d1	d2	l	h1	h2	a	b	⚖
GN.21202	GN 206.1-16-M8-NI	16	M8	56	12	34	7	12	53
GN.21212	GN 206.1-20-M10-NI	20	M10	70	14	42	9	14	98
GN.21222	GN 206.1-25-M12-NI	25	M12	87	18	53	11	18	200
GN.21232	GN 206.1-32-M16-NI	32	M16	109	22	66	15	22	396
GN.21242	GN 206.1-40-M20-NI	40	M20	140	28	84	18	28	720

