



1



2



3



4



5



6



7



8



9



10



11



12



13



14



15



16



17



18



19



20



21



22



23



24



25



26



27



28



MATERIAL

Round cross section bar.
GN 224.1: chrome-plated steel.
GN 224.5: AISI 304 stainless steel, brushed matte finish.

WASHERS

GN 224.1: nickel-plated zinc alloy.
GN 224.5: AISI 304 stainless steel.

MATERIAL


Glass-fibre reinforced polyamide based (PA) technopolymer.

COLOUR




Black, semi-matte finish.

STANDARD EXECUTION

Tapped brass boss.

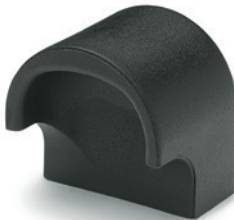

Conversion Table 1 mm = 0.039 inch			
d1		L	
mm	inch	mm	inch
8	0.31	26	1.02
10	0.39	30	1.18

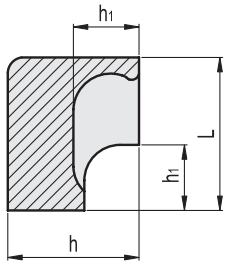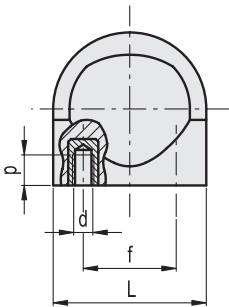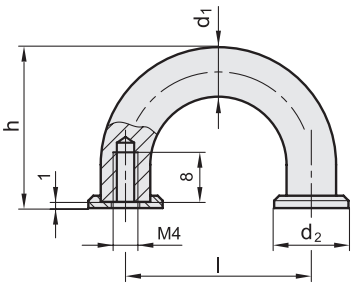

GN 224.1

Code	Description	d1	l	d2	h	⚖
GN.10381	GN 224.1-8-30-CR	8	30±0.25	12	26	20
GN.10382	GN 224.1-10-40-CR	10	40±0.25	15	31	40

METRIC

GN 224.5

Code	Description	d1	l	d2	h	⚖
GN.10385	GN 224.5-8-30	8	30±0.25	12	26	20
GN.10386	GN 224.5-10-40	10	40±0.25	15	31	40



METRIC

Code	f	L	d	p	h	h1	⚖
RHFM-14.022.9005	14	26	M4	6	22	11	15
RHFM-18.026.9005	18	30	M4	6	26	13	21

METRIC