


STANDARD EXECUTIONS

- **GN 252:** black-oxide steel (class 5.8 - tensile strength 500 N/mm²).
- **GN 252.5:** AISI 303 stainless steel.




SPECIAL EXECUTIONS ON REQUEST

The application of a layer made out of polyamide (blue colour) on the thread with locking action (GN 252-PRB, GN 252.5-PRB), (see Technical data on page A-19).

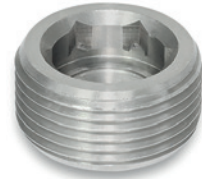

Application example

  GN 252-PRB
GN 252.5-PRB

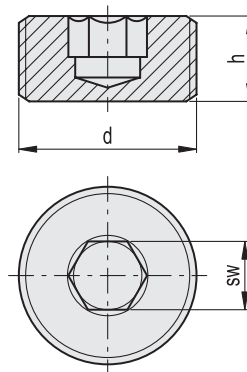

Conversion Table	
1 mm = 0.039 inch	
h	
mm	inch
10	0.39
12	0.47

GN 252

METRIC

Code	Description	d	h	sw	⚖️
GN.25451	GN 252-M12X1,5-A	M12X1,5	10	6	6
GN.25453	GN 252-M16X1,5-A	M16X1,5	10	8	10
GN.25455	GN 252-M20X1,5-A	M20X1,5	12	10	20
GN.25457	GN 252-M24X1,5-A	M24X1,5	12	14	24
GN.25459	GN 252-M27X1,5-A	M27X1,5	12	14	36
GN.25461	GN 252-M30X1,5-A	M30X1,5	12	17	44
GN.25463	GN 252-M33X1,5-A	M33X1,5	12	17	56

GN 252.5

INOX STAINLESS STEEL **METRIC**

Code	Description	d	h	sw	⚖️
GN.25481	GN 252.5-M12X1,5-A	M12X1,5	10	6	6
GN.25483	GN 252.5-M16X1,5-A	M16X1,5	10	8	10
GN.25485	GN 252.5-M20X1,5-A	M20X1,5	12	10	20
GN.25487	GN 252.5-M24X1,5-A	M24X1,5	12	14	24
GN.25489	GN 252.5-M27X1,5-A	M27X1,5	12	14	36

