







MATERIAL

Cast AISI CF-8 stainless steel, sandblasted matte finish.

FEATURES AND APPLICATIONS

GN 271-NI bases can be assembled with pivoting connecting clamps GN 273-NI (see page 1753), GN 275-NI (see page 1756) or GN 277-NI (see page 1757).

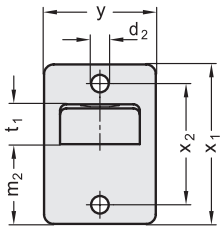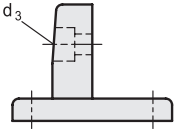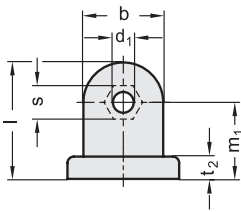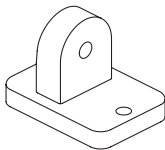

Conversion Table	
1 mm = 0.039 inch	
	b
mm	inch
25	0.98

Code	Description	b	d1	d2	d3	l	m1	m2	t1	t2	s	x1	x2	y	Δ
GN.56903	GN 271-25-NI	25	6.5	5.5	M6	36.5	24	25	12.5	7	10	50	38	35	128

INOX STAINLESS STEEL

METRIC

Connecting clamps