





MATERIAL

Aluminium.
Surface finish index:
- **BL**: natural colour.
- **SW**: epoxy resin coating resistant to UV rays, RAL 9005 black colour.

FEATURES AND APPLICATIONS

GN 271 bases can be assembled with pivoting connecting clamps GN 273 (see page 1343), GN 275 (see page 1346) or GN 277 (see page 1347).

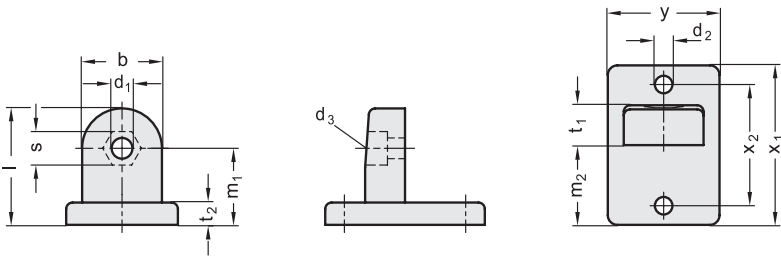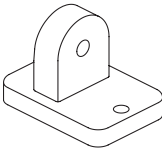

Conversion Table	
1 mm = 0.039 inch	
b	
mm	inch
25	0.98

Code	Description	b	d1	d2	d3	l	m1	m2	t1	t2	s	x1	x2	y	△
GN.56906	GN 271-25-SW	25	6.5	5.5	M6	36.5	24	25	12.5	7	10	50	38	35	44
GN.56901	GN 271-25-BL	25	6.5	5.5	M6	36.5	24	25	12.5	7	10	50	38	35	44