





STANDARD EXECUTIONS

Holes for countersunk screws **A**

- **GN 3136-ST**: zinc-plated steel, blue passivated.
- **GN 3136-NI**: AISI 304 stainless steel, polished finish.

FEATURES AND APPLICATIONS

GN 3136 folding handles are used to open drawers or lift boxes and containers. During use, the revolving handle hits the sheet metal housing at approximately 90° and then returns to its stop position by gravity. Thanks to their simple construction, the moulded and folded parts can have greater tolerances. Therefore, suitable compensation measures must be taken into account in the design.

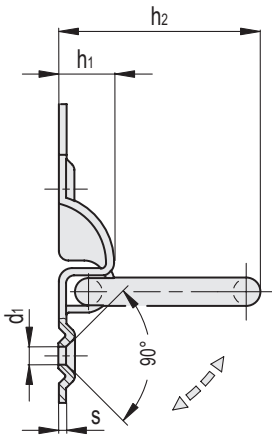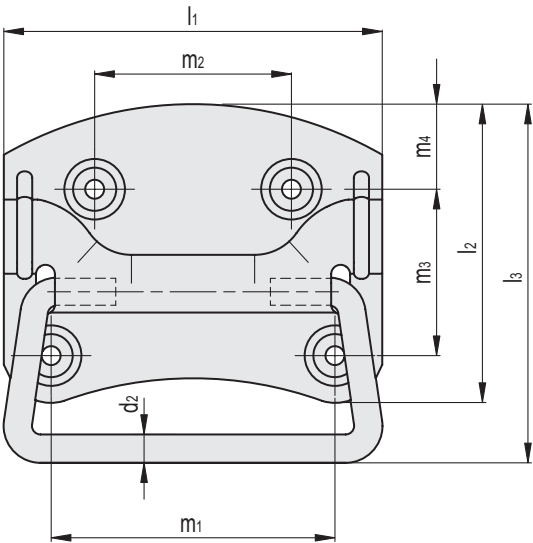

Conversion Table	
1 mm = 0.039 inch	
l1	
mm	inch
85	3.32
100	3.90
120	4.68
135	5.27

GN 3136-ST

METRIC

Code	Description	l1	l2	l3	d1	d1 For screws	d2	h1	h2	m1	m2	m3	m4	s	⚖
GN.81021	GN 3136-85-70-A-ST	85	70	75	5.5	M 4	6.5	12	44	65	45	45	10	1.25	101
GN.81023	GN 3136-100-80-A-ST	100	80	95	5.5	M 4 / M 5	7.5	14	52	75	52	44	22.5	1.5	161
GN.81024	GN 3136-120-95-A-ST	120	95	103.5	5.5	M 5	7.5	15	54	96	70	55	20	1.5	200
GN.81025	GN 3136-135-110-A-ST	135	110	123	6.4	M 6	10	15	65	105	75	73	22	1.75	371

GN 3136-NI

INOX
STAINLESS
STEEL

Code	Description	l1	l2	l3	d1	d1 For screws	d2	h1	h2	m1	m2	m3	m4	s	⚖
GN.81022	GN 3136-100-80-A-NI	100	80	95	5.5	M 4 / M 5	7.5	14	52	75	52	44	22.5	1.5	160