

STANDARD EXECUTIONS

Die-cast zinc alloy handle shanks, with epoxy resin coating, threaded blind holes. Fixation to the tube by means of two screws.

- **GN 333-EL:** anodised aluminium tube, natural colour. Handle shanks RAL 9005 black colour, matte finish.
- **GN 333-ES:** anodised aluminium tube, natural colour. Handle shanks RAL 9006 grey colour, matte finish.
- **GN 333-SW:** aluminium tube covered with epoxy resin, RAL 9005 black colour, matte finish. Handle shanks RAL 9005 black colour, matte finish.

END CAPS

Polyamide based (PA) technopolymer, light grey colour.

FEATURES AND APPLICATIONS


Two screws tighten the tube to the handle shanks, preventing rotation. These handles are typically used on turning or rolling doors.

SPECIAL EXECUTIONS ON REQUEST

- Different lengths.
- GN 333.2: tubular handles with movable handle shanks.



Conversion Table	
1 mm = 0.039 inch	
mm	inch
180	7.09
200	7.87
300	11.81
400	15.75
500	19.69

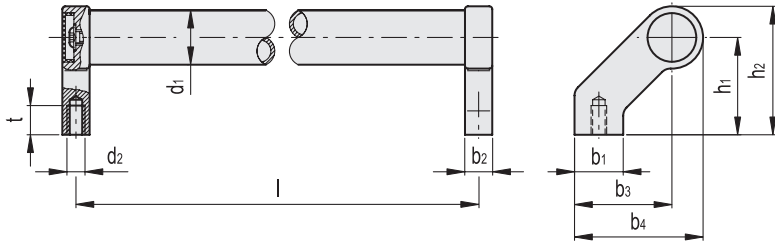

METRIC

Code	Description	d1	ls0.25	d2	b1	b2	b3	b4	h1	h2	tmin	⚖
GN.27698	GN 333-20-180-A-EL	20	180	M6	24	12	42	54	42	54	12	242
GN.27699	GN 333-20-180-A-ES	20	180	M6	24	12	42	54	42	54	12	242
GN.27700	GN 333-20-180-A-SW	20	180	M6	24	12	42	54	42	54	12	242
GN.27701	GN 333-20-200-A-EL	20	200	M6	24	12	42	54	42	54	12	246
GN.27702	GN 333-20-200-A-ES	20	200	M6	24	12	42	54	42	54	12	246
GN.27703	GN 333-20-200-A-SW	20	200	M6	24	12	42	54	42	54	12	246
GN.27704	GN 333-20-300-A-EL	20	300	M6	24	12	42	54	42	54	12	283
GN.27705	GN 333-20-300-A-ES	20	300	M6	24	12	42	54	42	54	12	283
GN.27706	GN 333-20-300-A-SW	20	300	M6	24	12	42	54	42	54	12	283
GN.27707	GN 333-20-400-A-EL	20	400	M6	24	12	42	54	42	54	12	321
GN.27708	GN 333-20-400-A-ES	20	400	M6	24	12	42	54	42	54	12	321
GN.27709	GN 333-20-400-A-SW	20	400	M6	24	12	42	54	42	54	12	321
GN.27661	GN 333-28-200-A-EL	28	200	M8	25	14	50	66	50	66	15	432
GN.27663	GN 333-28-200-A-ES	28	200	M8	25	14	50	66	50	66	15	432
GN.27662	GN 333-28-200-A-SW	28	200	M8	25	14	50	66	50	66	15	432
GN.27665	GN 333-28-300-A-EL	28	300	M8	25	14	50	66	50	66	15	470
GN.27667	GN 333-28-300-A-ES	28	300	M8	25	14	50	66	50	66	15	470
GN.27666	GN 333-28-300-A-SW	28	300	M8	25	14	50	66	50	66	15	470
GN.27671	GN 333-28-500-A-EL	28	500	M8	25	14	50	66	50	66	15	535
GN.27673	GN 333-28-500-A-ES	28	500	M8	25	14	50	66	50	66	15	535
GN.27672	GN 333-28-500-A-SW	28	500	M8	25	14	50	66	50	66	15	535