

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18

DISK

Zinc-plated steel.

STANDARD EXECUTIONS


- **GN 338-KS**: acetal resin based (POM) technopolymer protection cap, white colour.
- **GN 338-KR**: thermoplastic elastomer (TPE) protection cap.

FEATURES AND APPLICATIONS


GN 338 disks with protection cap can be used as feet on machinery, as sliding bases on mechanical devices provided with very sensitive equipment (GN 338-KS) or more simply as covers for screw heads to enhance their look when fitted.



Application examples

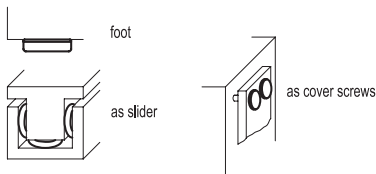

| Conversion Table | |
|-------------------|------|
| 1 mm = 0.039 inch | |
| d1 | |
| mm | inch |
| 16 | 0.63 |
| 20 | 0.79 |
| 25 | 0.98 |
| 32 | 1.26 |

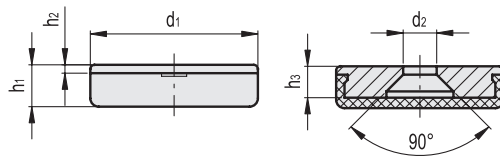

METRIC

| Code | Description | d1 | d2 | h1 | h2 | h3 | △ |
|----------|--------------|----|-----|-----|----|-----|----|
| GN.14902 | GN 338-16-KS | 16 | 3.2 | 5 | 1 | 3.7 | 5 |
| GN.14912 | GN 338-20-KS | 20 | 4.3 | 5 | 1 | 3.7 | 7 |
| GN.14922 | GN 338-25-KS | 25 | 4.3 | 5.7 | 1 | 4 | 14 |
| GN.14932 | GN 338-32-KS | 32 | 5.3 | 6.7 | 1 | 5 | 28 |
| GN.14901 | GN 338-16-KR | 16 | 3.2 | 5 | 1 | 3.7 | 4 |
| GN.14911 | GN 338-20-KR | 20 | 4.3 | 5 | 1 | 3.7 | 7 |
| GN.14921 | GN 338-25-KR | 25 | 4.3 | 5.7 | 1 | 4 | 12 |
| GN.14931 | GN 338-32-KR | 32 | 5.3 | 6.7 | 1 | 5 | 24 |

Machine elements
1006