

HOUSING, MOUNTING RING AND HANDLE

Stainless Steel AISI 304

- Polished finish **PL**
- Socket cap screws

CLOSURE AND STOP

Stainless Steel AISI 304

STANDARD EXECUTIONS

- **GN 449.5-OS:** without lock
- **GN 449.5-SC:** with lock

LOCK

AISI 316 stainless steel

KEY

Brass, nickel plated



FEATURES AND APPLICATIONS

The GN 449.5 snap door lock combines the function of a recessed handle with that of a snap mechanism to ensure that doors, hatches and covers are securely closed.

After drilling the mounting hole in the door, insert the housing into it and push the mounting ring into place from the rear. Secure the housing and mounting ring using the two cylindrical head screws provided.

The stop is mounted on the door profile or frame perpendicular to the snap element, in accordance with the measurements.

The SC execution snap door lock is equipped with a key. The key can be removed from both end positions. The locking mechanism is standard, so the same key can open all locks.

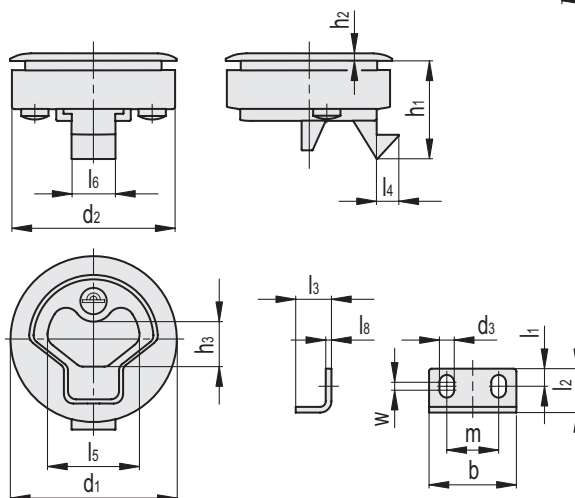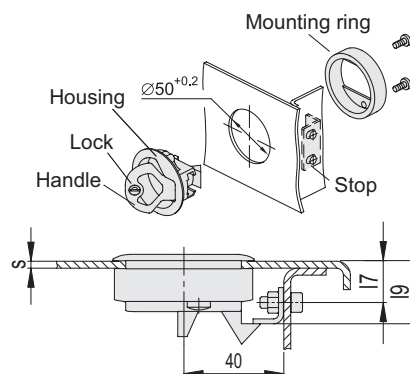

Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
61	2.38

GN 449.5-OS

Code	Description	Wall thickness Nominal dimension	Wall thickness s	l1	b	h1	h2	h3	d1	d2	d3	l2	l3	l4	l5	l6	l7	l8	l9	m	w	⚖	
GN.45251	GN 449.5-61-OS-PL	A 1	1 - 5	6,5	32	36	3	16,5	61	60	5,5	16	13	8	33,5	16	18	1,2	27,5	19,5	3	280	

GN 449.5-SC

Code	Description	Wall thickness Nominal dimension	Wall thickness s	l1	b	h1	h2	h3	d1	d2	d3	l2	l3	l4	l5	l6	l7	l8	l9	m	w	⚖	
GN.45256	GN 449.5-61-SC-PL	A 1	1 - 5	6,5	32	36	3	16,5	61	60	5,5	16	13	8	33,5	16	18	1,2	27,5	19,5	3	280	