

TYPE

- Type L: L-shaped

IDENTIFICATION NO.

- 1: short
- 2: long

AISI 316 stainless steel **A4**
Matte shot-blasted finish **GS**

INFORMATION




Mounting plates GN 4490.1 enable the use of ball catches GN 4490 (see page) in various installation situations. The positioning is facilitated by slotted holes.

ACCESSORIES

- GN 50B:T-Nuts (see page).
- GN 50I:T-Nuts (see page).
- GN 51B:T-Nuts (see page).



Application examples

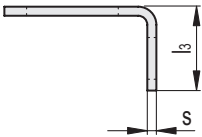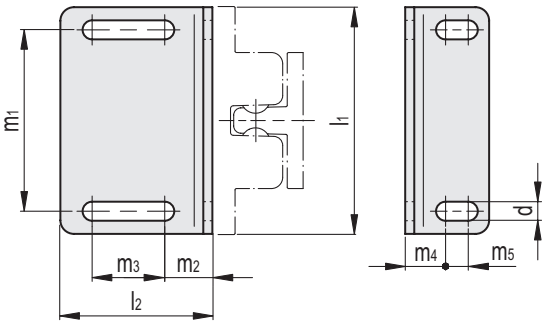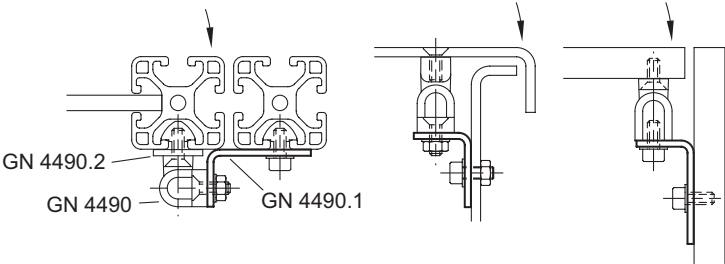

Conversion Table
1 mm = 0.039 inch

l1

mm	inch
50	1.95
68	2.65
80	3.12

GN 4490.1-L-1

Code	Description	l1	l2	l3	d	m1	m2	m3	m4	m5	s	For aluminum profiles	⚖
GN.22832	GN 4490.1-A4-50-L-1-GS	50	22	18.5	4.2	40	9.5	7	8.9	5	2	20	18
GN.22834	GN 4490.1-A4-68-L-1-GS	68	32	21.5	4.2	55	11	14	9.5	7	2	30	22

GN 4490.1-L-2

Code	Description	l1	l2	l3	d	m1	m2	m3	m4	m5	s	For aluminum profiles	⚖
GN.22833	GN 4490.1-A4-50-L-2-GS	50	33.5	18.5	4.2	40	11	15.5	8.9	5	2	30	18
GN.22835	GN 4490.1-A4-68-L-2-GS	68	51	21.5	4.2	55	11	33	9.5	7	2	40 / 45	22
GN.22836	GN 4490.1-A4-80-L-2-GS	80	49	24.5	5.2	65	11	31	11.5	7	2	40 / 45	24