





- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18
- 19

**MAIN SPECIFICATIONS**

- Zinc-plated steel, blue passivated **SZ**
- Stainless steel, plain finish **NB**

**FEATURES AND APPLICATIONS**

T-slot bolts GN 52B fasten attachments and accessories in the slot of aluminum profiles. They are inserted into the slot of the aluminum profile at any position and affixed by a 90° turn. The connection is conductive.

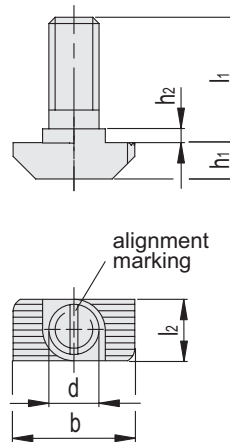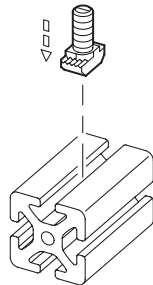

Conversion Table	
1 mm = 0.039 inch	
b	
mm	inch
16	0.62
19.5	0.76

**GN 52B-SZ**

**METRIC**

Code	Description	b	n	d	l1	l2	h1	h2	⚙
GN.52352	GN 52B-8M616-SZ	16	8	M6	16	8	4.5	1.5	6
GN.52354	GN 52B-8M620-SZ	16	8	M6	20	8	4.5	1.5	7
GN.52356	GN 52B-8M625-SZ	16	8	M6	25	8	4.5	1.5	8
GN.52358	GN 52B-8M630-SZ	16	8	M6	30	8	4.5	1.5	9
GN.52360	GN 52B-8M640-SZ	16	8	M6	40	8	4.5	1.5	10
GN.52362	GN 52B-8M660-SZ	16	8	M6	60	8	4.5	1.5	12
GN.52364	GN 52B-8M820-SZ	16	8	M8	20	8	4.5	1.5	9
GN.52366	GN 52B-8M825-SZ	16	8	M8	25	8	4.5	1.5	10
GN.52368	GN 52B-8M830-SZ	16	8	M8	30	8	4.5	1.5	12
GN.52372	GN 52B-10M616-SZ	19.5	10	M6	16	8.5	5.5	4	6
GN.52374	GN 52B-10M620-SZ	19.5	10	M6	20	8.5	5.5	4	7
GN.52376	GN 52B-10M625-SZ	19.5	10	M6	25	8.5	5.5	4	8
GN.52378	GN 52B-10M630-SZ	19.5	10	M6	30	8.5	5.5	4	9
GN.52380	GN 52B-10M640-SZ	19.5	10	M6	40	8.5	5.5	4	10
GN.52382	GN 52B-10M660-SZ	19.5	10	M6	60	8.5	5.5	4	11
GN.52384	GN 52B-10M820-SZ	19.5	10	M8	20	8.5	5.5	4	14
GN.52386	GN 52B-10M825-SZ	19.5	10	M8	25	8.5	5.5	4	10
GN.52388	GN 52B-10M830-SZ	19.5	10	M8	30	8.5	5.5	4	17
GN.52390	GN 52B-10M840-SZ	19.5	10	M8	40	8.5	5.5	4	20
GN.52392	GN 52B-10M860-SZ	19.5	10	M8	60	8.5	5.5	4	26

**GN 52B-NB**

**INOX STAINLESS STEEL**

**METRIC**

Code	Description	b	n	d	l1	l2	h1	h2	⚙
GN.52353	GN 52B-8M620-NB	16	8	M6	20	8	4.5	1.5	8
GN.52355	GN 52B-8M625-NB	16	8	M6	25	8	4.5	1.5	9
GN.52357	GN 52B-8M630-NB	16	8	M6	30	8	4.5	1.5	10
GN.52359	GN 52B-8M640-NB	16	8	M6	40	8	4.5	1.5	11
GN.52361	GN 52B-8M660-NB	16	8	M6	60	8	4.5	1.5	14
GN.52373	GN 52B-10M620-NB	19.5	10	M6	20	8.5	5.5	4	11
GN.52375	GN 52B-10M625-NB	19.5	10	M6	25	8.5	5.5	4	12
GN.52377	GN 52B-10M630-NB	19.5	10	M6	30	8.5	5.5	4	13
GN.52379	GN 52B-10M640-NB	19.5	10	M6	40	8.5	5.5	4	15
GN.52381	GN 52B-10M660-NB	19.5	10	M6	60	8.5	5.5	4	19
GN.52383	GN 52B-10M820-NB	19.5	10	M8	20	8.5	5.5	4	15
GN.52385	GN 52B-10M825-NB	19.5	10	M8	25	8.5	5.5	4	16
GN.52387	GN 52B-10M830-NB	19.5	10	M8	30	8.5	5.5	4	18
GN.52389	GN 52B-10M840-NB	19.5	10	M8	40	8.5	5.5	4	21
GN.52391	GN 52B-10M860-NB	19.5	10	M8	60	8.5	5.5	4	27

Standard machine parts