



STANDARD EXECUTIONS

Aluminium, oval cross section bar.

Threaded blind holes.

Surface finish index:


- **BL**: natural colour.
- **EL**: anodised, natural colour.
- **RS**: epoxy resin coating, RAL 3000 red colour, matte finish.
- **SR**: epoxy resin coating, RAL 9006 silver colour, matte finish.
- **SW**: epoxy resin coating resistant to UV rays, RAL 9005 black colour, matte finish.

SPECIAL EXECUTIONS ON REQUEST

Lengths and colours other than the standard executions.



Conversion Table	
1 mm = 0.039 inch	
mm	inch
100	3.90
112	4.37
117	4.56
120	4.68
125	4.87
128	4.99
160	6.24
179	6.98
180	7.02
192	7.49
200	7.80
235	9.17
300	11.70
400	15.60
500	19.50

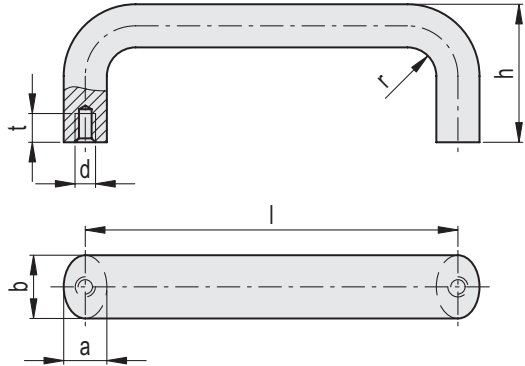

GN 565-SW

METRIC

Code	Description	b	d	l±0.25	a	h	r	tmin	⚖
GN.27092	GN 565-20-100-SW	20	M6	100	13	49	13	10	87
GN.27096	GN 565-20-112-SW	20	M6	112	13	49	13	10	97
GN.27072	GN 565-20-117-SW	20	M6	117	13	49	13	10	100
GN.27075	GN 565-20-120-SW	20	M6	120	13	49	13	10	105
GN.27102	GN 565-20-128-SW	20	M6	128	13	51	13	10	107
GN.27106	GN 565-20-160-SW	20	M6	160	13	51	13	10	127
GN.27163	GN 565-20-180-SW	20	M6	180	13	51	13	10	138
GN.27166	GN 565-20-200-SW	20	M6	200	13	51	13	10	150
GN.27169	GN 565-20-235-SW	20	M6	235	13	51	13	10	172
GN.27108	GN 565-26-112-SW	26	M8	112	17	55	17	12	160
GN.27078	GN 565-26-117-SW	26	M8	117	17	55	17	12	166
GN.27081	GN 565-26-120-SW	26	M8	120	17	55	17	12	170
GN.27084	GN 565-26-125-SW	26	M8	125	17	55	17	12	178
GN.27110	GN 565-26-128-SW	26	M8	128	17	55	17	12	183
GN.27112	GN 565-26-160-SW	26	M8	160	17	57	17	12	211
GN.27087	GN 565-26-179-SW	26	M8	179	17	57	17	12	230
GN.27116	GN 565-26-192-SW	26	M8	192	17	57	17	12	245
GN.27122	GN 565-26-300-SW	26	M8	300	17	57	17	12	350
GN.27126	GN 565-26-400-SW	26	M8	400	17	57	17	12	445
GN.27090	GN 565-26-500-SW	26	M8	500	17	57	17	12	538

Conversion Table	
1 mm = 0.039 inch	
mm	inch
100	3.90
112	4.37
117	4.56
120	4.68
125	4.87
128	4.99
160	6.24
179	6.98
180	7.02
192	7.49
200	7.80
235	9.17
300	11.70
400	15.60
500	19.50

GN 565

METRIC

Code	Description	b	d	l±0.25	a	h	r	tmin	Δ
GN.27091	GN 565-20-100-BL	20	M6	100	13	49	13	10	87
GN.27095	GN 565-20-112-BL	20	M6	112	13	49	13	10	97
GN.27070	GN 565-20-117-BL	20	M6	117	13	49	13	10	100
GN.27073	GN 565-20-120-BL	20	M6	120	13	49	13	10	105
GN.27101	GN 565-20-128-BL	20	M6	128	13	51	13	10	107
GN.27105	GN 565-20-160-BL	20	M6	160	13	51	13	10	127
GN.27161	GN 565-20-180-BL	20	M6	180	13	51	13	10	138
GN.27164	GN 565-20-200-BL	20	M6	200	13	51	13	10	150
GN.27167	GN 565-20-235-BL	20	M6	235	13	51	13	10	172
GN.27107	GN 565-26-112-BL	26	M8	112	17	55	17	12	160
GN.27076	GN 565-26-117-BL	26	M8	117	17	55	17	12	166
GN.27079	GN 565-26-120-BL	26	M8	120	17	55	17	12	170
GN.27082	GN 565-26-125-BL	26	M8	125	17	55	17	12	178
GN.27109	GN 565-26-128-BL	26	M8	128	17	55	17	12	183
GN.27111	GN 565-26-160-BL	26	M8	160	17	57	17	12	211
GN.27085	GN 565-26-179-BL	26	M8	179	17	57	17	12	230
GN.27115	GN 565-26-192-BL	26	M8	192	17	57	17	12	245
GN.27121	GN 565-26-300-BL	26	M8	300	17	57	17	12	350
GN.27125	GN 565-26-400-BL	26	M8	400	17	57	17	12	445
GN.27088	GN 565-26-500-BL	26	M8	500	17	57	17	12	538
GN.27131	GN 565-20-100-EL	20	M6	100	13	49	13	10	87
GN.27132	GN 565-20-112-EL	20	M6	112	13	49	13	10	97
GN.27071	GN 565-20-117-EL	20	M6	117	13	49	13	10	100
GN.27074	GN 565-20-120-EL	20	M6	120	13	49	13	10	105
GN.27133	GN 565-20-128-EL	20	M6	128	13	51	13	10	107
GN.27134	GN 565-20-160-EL	20	M6	160	13	51	13	10	127
GN.27162	GN 565-20-180-EL	20	M6	180	13	51	13	10	138
GN.27165	GN 565-20-200-EL	20	M6	200	13	51	13	10	150
GN.27168	GN 565-20-235-EL	20	M6	235	13	51	13	10	172
GN.27141	GN 565-26-112-EL	26	M8	112	17	55	17	12	160
GN.27077	GN 565-26-117-EL	26	M8	117	17	55	17	12	166
GN.27080	GN 565-26-120-EL	26	M8	120	17	55	17	12	170
GN.27083	GN 565-26-125-EL	26	M8	125	17	55	17	12	178
GN.27142	GN 565-26-128-EL	26	M8	128	17	55	17	12	183
GN.27143	GN 565-26-160-EL	26	M8	160	17	57	17	12	211
GN.27086	GN 565-26-179-EL	26	M8	179	17	57	17	12	230
GN.27144	GN 565-26-192-EL	26	M8	192	17	57	17	12	245
GN.27145	GN 565-26-300-EL	26	M8	300	17	57	17	12	350
GN.27089	GN 565-26-500-EL	26	M8	500	17	57	17	12	538
GN.27146	GN 565-26-400-EL	26	M8	400	17	57	17	12	445

METRIC

Code	Description	b	d	l±0.25	a	h	r	tmin	Δ
GN.64681	GN 565-20-100-RS	20	M6	100	13	49	13	10	87
GN.64686	GN 565-20-112-RS	20	M6	112	13	49	13	10	93
GN.64691	GN 565-20-117-RS	20	M6	117	13	49	13	10	100
GN.64696	GN 565-20-120-RS	20	M6	120	13	49	13	10	107
GN.64701	GN 565-20-128-RS	20	M6	128	13	51	13	10	114
GN.64706	GN 565-20-160-RS	20	M6	160	13	51	13	10	121
GN.64711	GN 565-20-180-RS	20	M6	180	13	51	13	10	128
GN.64716	GN 565-20-200-RS	20	M6	200	13	51	13	10	150
GN.64721	GN 565-20-235-RS	20	M6	235	13	51	13	10	172
GN.64726	GN 565-26-112-RS	26	M8	112	17	55	17	12	161
GN.64731	GN 565-26-117-RS	26	M8	117	17	55	17	12	166
GN.64736	GN 565-26-120-RS	26	M8	120	17	55	17	12	171
GN.64741	GN 565-26-125-RS	26	M8	125	17	55	17	12	180
GN.64746	GN 565-26-128-RS	26	M8	128	17	55	17	12	189
GN.64751	GN 565-26-160-RS	26	M8	160	17	57	17	12	210
GN.64756	GN 565-26-179-RS	26	M8	179	17	57	17	12	234
GN.64761	GN 565-26-192-RS	26	M8	192	17	57	17	12	245
GN.64766	GN 565-26-300-RS	26	M8	300	17	57	17	12	345
GN.64771	GN 565-26-400-RS	26	M8	400	17	57	17	12	440
GN.64776	GN 565-26-500-RS	26	M8	500	17	57	17	12	538
GN.64683	GN 565-20-100-SR	20	M6	100	13	49	13	10	87
GN.64688	GN 565-20-112-SR	20	M6	112	13	49	13	10	93
GN.64693	GN 565-20-117-SR	20	M6	117	13	49	13	10	100
GN.64698	GN 565-20-120-SR	20	M6	120	13	49	13	10	107
GN.64703	GN 565-20-128-SR	20	M6	128	13	51	13	10	114
GN.64708	GN 565-20-160-SR	20	M6	160	13	51	13	10	121
GN.64713	GN 565-20-180-SR	20	M6	180	13	51	13	10	128
GN.64718	GN 565-20-200-SR	20	M6	200	13	51	13	10	150
GN.64723	GN 565-20-235-SR	20	M6	235	13	51	13	10	172
GN.64728	GN 565-26-112-SR	26	M8	112	17	55	17	12	161
GN.64733	GN 565-26-117-SR	26	M8	117	17	55	17	12	166
GN.64738	GN 565-26-120-SR	26	M8	120	17	55	17	12	171
GN.64743	GN 565-26-125-SR	26	M8	125	17	55	17	12	180
GN.64748	GN 565-26-128-SR	26	M8	128	17	55	17	12	189
GN.64753	GN 565-26-160-SR	26	M8	160	17	57	17	12	210
GN.64758	GN 565-26-179-SR	26	M8	179	17	57	17	12	234
GN.64763	GN 565-26-192-SR	26	M8	192	17	57	17	12	245
GN.64768	GN 565-26-300-SR	26	M8	300	17	57	17	12	345
GN.64773	GN 565-26-400-SR	26	M8	400	17	57	17	12	440
GN.64778	GN 565-26-500-SR	26	M8	500	17	57	17	12	538

