



1



2



3



4



5



6



7



8



9



10



11



12



13



14



15



16



17



18

TYPES

- Type **D**: with threaded through bore
- Type **E**: with threaded blind bore

Stainless Steel precision casting **A4**


- AISI 316

- polished **PL**

FEATURES AND APPLICATIONS

Star knobs GN 6336 satisfy the dimensions of the DIN 6336 (see page) but differ in terms of their non-scooping geometry, which makes cleaning easier and helps prevent possible build-up of dirt.

They are suitable for areas with special hygiene requirements and, thanks to the material used, for applications in highly corrosive environments.

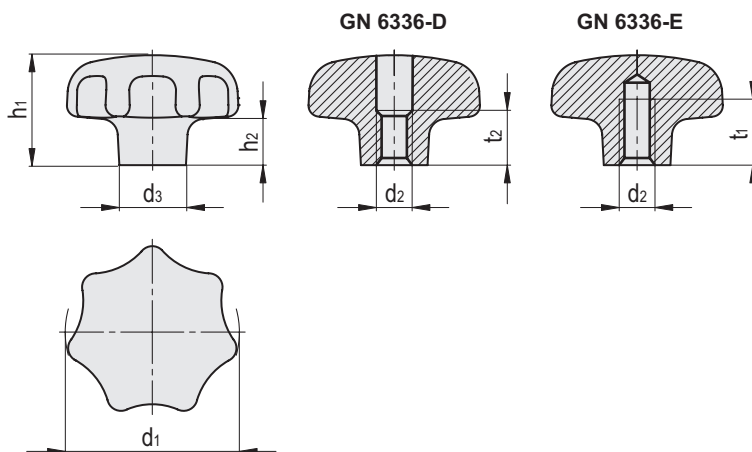

Conversion Table

1 mm = 0,039 inch

d1	
mm	inch
32	1.26
40	1.57
50	1.97
63	2.48

GN 6336-D

Code	Description	d1	d2	d3	h1	h2	t2	⚖
GN.28891	GN 6336-A4-32-M6-D-PL	32	M 6	12	20	9	10	54
GN.28896	GN 6336-A4-40-M8-D-PL	40	M 8	14	25	12	13	103
GN.28901	GN 6336-A4-50-M10-D-PL	50	M 10	18	32	15	16	208
GN.28906	GN 6336-A4-63-M12-D-PL	63	M 12	20	40	19	20	378

INOX
STAINLESS
STEEL

METRIC

GN 6336-E

Code	Description	d1	d2	d3	h1	h2	t1 min	⚖
GN.28892	GN 6336-A4-32-M6-E-PL	32	M 6	12	20	9	12	65
GN.28897	GN 6336-A4-40-M8-E-PL	40	M 8	14	25	12	15	106
GN.28902	GN 6336-A4-50-M10-E-PL	50	M 10	18	32	15	18	210
GN.28907	GN 6336-A4-63-M12-E-PL	63	M 12	20	40	19	22	395

INOX
STAINLESS
STEEL

METRIC