



- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18

STANDARD EXECUCION


Transparent polyurethane (PUR), hardness 70 Shore A. Resistant up to 80°C.

With adhesive tape.




FEATURES AND APPLICATIONS

GN 7072.30 dampening washers are accessories for the different types of set collars. They are fixed by means of an adhesive film, preferably on the side of the set collar without grooves.

They allow to absorb light impacts and have got a dampening effect when they come into contact with other components.

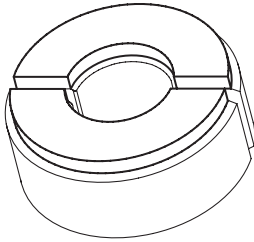

Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
30	1.18
32	1.26
36	1.42
42	1.65
48	1.89
55	2.17
60	2.36
65	2.56

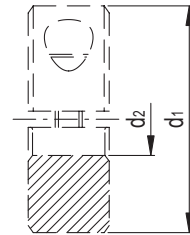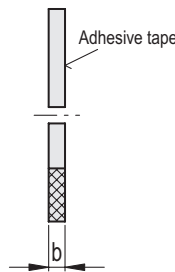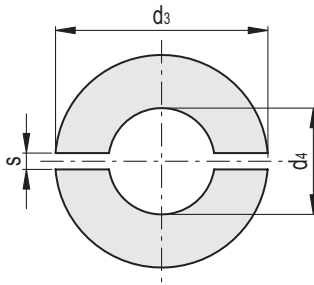

METRIC

Code	Description	d1	d2	d3	d4	b±0.2	s	⚖️
GN.75001	GN 7072.30-30-B12	30	12	28	13	2	2.1	1
GN.75002	GN 7072.30-32-B14	32	14	30	15	2	2.1	1
GN.75006	GN 7072.30-36-B15	36	15	34	16	2	2.1	2
GN.75007	GN 7072.30-36-B16	36	16	34	17	2	2.1	2
GN.75011	GN 7072.30-42-B18	42	18	39	19.5	3	3	3
GN.75012	GN 7072.30-42-B20	42	20	39	21.5	3	3	3
GN.75016	GN 7072.30-48-B22	48	22	45	23.5	3	3	4
GN.75017	GN 7072.30-48-B25	48	25	45	26.5	3	3	4
GN.75021	GN 7072.30-55-B28	55	28	52	29.5	3	3	5
GN.75022	GN 7072.30-55-B30	55	30	52	31.5	3	3	5
GN.75026	GN 7072.30-60-B32	60	32	57	33.5	3	4	6
GN.75027	GN 7072.30-60-B35	60	35	57	36.5	3	4	6
GN.75031	GN 7072.30-65-B40	65	40	62	41.5	3	4	6