


MATERIAL


Turned and black-oxide steel, class 5.8 (tensile strength 500 N/mm²).

FEATURES AND APPLICATIONS

d2 and l1 dimensions can be used with GN 732 shoulder screws together with eye screws DIN 444 (see page 790), eye nuts type GN 444.2 (see page 791) hubs with eccentric cam type GN 919 (see page 822).

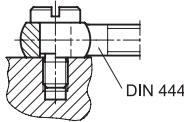

| Conversion Table  |      |
|-------------------|------|
| 1 mm = 0.039 inch |      |
| d2                |      |
| mm                | inch |
| 6                 | 0.24 |
| 8                 | 0.31 |
| 10                | 0.39 |
| 12                | 0.47 |
| 14                | 0.55 |

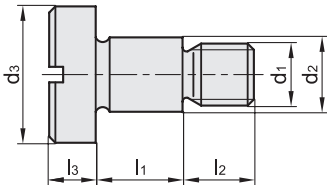

| Code     | Description      | d1  | d2             | d3 | l1 +0.25 +0.13 | l2 | l3 |    |
|----------|------------------|-----|----------------|----|----------------|----|----|----|
| GN.27741 | GN 732-M5-6-5    | M5  | 6 -0.03/-0.05  | 12 | 5              | 7  | 3  | 4  |
| GN.27742 | GN 732-M5-6-6    | M5  | 6 -0.03/-0.05  | 12 | 6              | 7  | 3  | 4  |
| GN.27743 | GN 732-M5-6-8    | M5  | 6 -0.03/-0.05  | 12 | 8              | 7  | 3  | 5  |
| GN.27746 | GN 732-M6-8-5    | M6  | 8 -0.05/-0.08  | 14 | 5              | 8  | 4  | 8  |
| GN.27747 | GN 732-M6-8-8    | M6  | 8 -0.05/-0.08  | 14 | 8              | 8  | 4  | 9  |
| GN.27748 | GN 732-M6-8-10   | M6  | 8 -0.05/-0.08  | 14 | 10             | 8  | 4  | 10 |
| GN.27751 | GN 732-M8-10-10  | M8  | 10 -0.05/-0.08 | 16 | 10             | 11 | 5  | 17 |
| GN.27752 | GN 732-M8-10-12  | M8  | 10 -0.05/-0.08 | 16 | 12             | 11 | 5  | 18 |
| GN.27753 | GN 732-M8-10-14  | M8  | 10 -0.05/-0.08 | 16 | 14             | 11 | 5  | 18 |
| GN.27756 | GN 732-M10-12-12 | M10 | 12 -0.05/-0.08 | 19 | 12             | 13 | 6  | 29 |
| GN.27757 | GN 732-M10-12-14 | M10 | 12 -0.05/-0.08 | 19 | 14             | 13 | 6  | 30 |
| GN.27758 | GN 732-M10-12-16 | M10 | 12 -0.05/-0.08 | 19 | 16             | 13 | 6  | 33 |
| GN.27761 | GN 732-M12-14-14 | M12 | 14 -0.05/-0.08 | 22 | 14             | 16 | 8  | 49 |
| GN.27762 | GN 732-M12-14-16 | M12 | 14 -0.05/-0.08 | 22 | 16             | 16 | 8  | 51 |
| GN.27763 | GN 732-M12-14-18 | M12 | 14 -0.05/-0.08 | 22 | 18             | 16 | 8  | 54 |