

TYPES

- Type **O**: neutral
- Type **E**: with DIN fill symbol
- Type **A**: with DIN drain symbol

IDENTIFICATION NO.

- No. **1**: Without vent drilling

AISI 316L stainless steel
Precision turned, plain finish

Ring

Fluoro-elastomer (FPM / FKM)

- Brown
- Temperature resistant up to 180 °C

FEATURES AND APPLICATIONS

Stainless steel threaded plugs GN 742.5 can be used in particularly aggressive environments thanks to the material used.

The seal is embedded in a radial recess and thus cannot be lost, squeezed out or overloaded during tightening.


The outer diameter d1 of the stainless steel threaded plugs GN 742.5 is matched to screw-in holes for pipe fittings according to DIN 3852.

ON REQUEST

- Other thread sizes
- With dipstick
- With acrylonitrile butadiene rubber (NBR) seal GN 741.5



Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
19	0.74
22	0.86
26	1.01
32	1.25
40	1.56

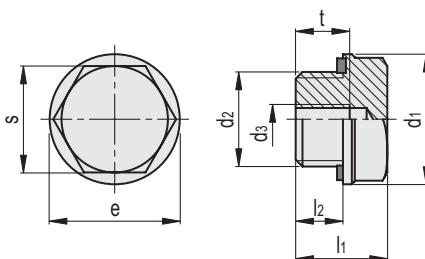


GN 742.5-O

INOX STAINLESS STEEL METRIC

Code	Description	d1	d2	d3	l1	l2	s	e	t	△
GN.72043	GN 742.5-19-G1/4-O-1	19	G 1/4	M 5	15.5	8	15	17.3	8	20
GN.72053	GN 742.5-22-G3/8-O-1	22	G 3/8	M 5	15.5	8	18	20.8	8	29
GN.72063	GN 742.5-26-G1/2-O-1	26	G 1/2	M 5	16	8.5	21	24.3	8	44
GN.72073	GN 742.5-32-G3/4-O-1	32	G 3/4	M 5	17	9	27	31.2	8	78
GN.72083	GN 742.5-40-G1-O-1	40	G 1	M 5	19.5	11	32	37	8	136
GN.72048	GN 742.5-19-M14X1,5-O-1	19	M14x1.5	M 5	15.5	8	15	17.3	8	20
GN.72058	GN 742.5-22-M16X1,5-O-1	22	M16x1.5	M 5	15.5	8	18	20.8	8	29
GN.72068	GN 742.5-26-M20X1,5-O-1	26	M20x1.5	M 5	16	8.5	21	24.3	8	44
GN.72078	GN 742.5-32-M26X1,5-O-1	32	M26x1.5	M 5	17	9	27	31.2	8	78
GN.72088	GN 742.5-40-M33X1,5-O-1	40	M33x1.5	M 5	19.5	11	32	37	8	136

Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
19	0.74
22	0.86
26	1.01
32	1.25
40	1.56

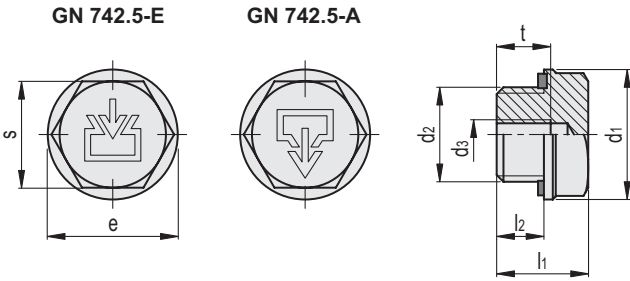

GN 742.5-E

		INOX STAINLESS STEEL METRIC								
Code	Description	d1	d2	d3	l1	l2	s	e	t	⚖
GN.72042	GN 742.5-19-G1/4-E-1	19	G 1/4	M 5	15.5	8	15	17.3	8	20
GN.72052	GN 742.5-22-G3/8-E-1	22	G 3/8	M 5	15.5	8	18	20.8	8	29
GN.72062	GN 742.5-26-G1/2-E-1	26	G 1/2	M 5	16	8.5	21	24.3	8	44
GN.72072	GN 742.5-32-G3/4-E-1	32	G 3/4	M 5	17	9	27	31.2	8	78
GN.72082	GN 742.5-40-G1-E-1	40	G 1	M 5	19.5	11	32	37	8	136
GN.72047	GN 742.5-19-M14X1,5-E-1	19	M14x1.5	M 5	15.5	8	15	17.3	8	20
GN.72057	GN 742.5-22-M16X1,5-E-1	22	M16x1.5	M 5	15.5	8	18	20.8	8	29
GN.72067	GN 742.5-26-M20X1,5-E-1	26	M20x1.5	M 5	16	8.5	21	24.3	8	44
GN.72077	GN 742.5-32-M26X1,5-E-1	32	M26x1.5	M 5	17	9	27	31.2	8	78
GN.72087	GN 742.5-40-M33X1,5-E-1	40	M33x1.5	M 5	19.5	11	32	37	8	136

GN 742.5-A

		INOX STAINLESS STEEL METRIC								
Code	Description	d1	d2	d3	l1	l2	s	e	t	⚖
GN.72041	GN 742.5-19-G1/4-A-1	19	G 1/4	M 5	15.5	8	15	17.3	8	20
GN.72051	GN 742.5-22-G3/8-A-1	22	G 3/8	M 5	15.5	8	18	20.8	8	29
GN.72061	GN 742.5-26-G1/2-A-1	26	G 1/2	M 5	16	8.5	21	24.3	8	44
GN.72071	GN 742.5-32-G3/4-A-1	32	G 3/4	M 5	17	9	27	31.2	8	78
GN.72081	GN 742.5-40-G1-A-1	40	G 1	M 5	19.5	11	32	37	8	136
GN.72046	GN 742.5-19-M14X1,5-A-1	19	M14x1.5	M 5	15.5	8	15	17.3	8	20
GN.72056	GN 742.5-22-M16X1,5-A-1	22	M16x1.5	M 5	15.5	8	18	20.8	8	29
GN.72066	GN 742.5-26-M20X1,5-A-1	26	M20x1.5	M 5	16	8.5	21	24.3	8	44
GN.72076	GN 742.5-32-M26X1,5-A-1	32	M26x1.5	M 5	17	9	27	31.2	8	78
GN.72086	GN 742.5-40-M33X1,5-A-1	40	M33x1.5	M 5	19.5	11	32	37	8	136

