



STANDARD EXECUTIONS

AISI 304 stainless steel pin and countersunk-head screw with hexagon socket.




- **GN 2342-B-1**: with AISI 304 stainless steel flat retaining washer.
- **GN 2342-B-2**: with AISI 304 stainless steel flat retaining washer, and transversal hole for GN 1024 spring cotter pins.
- **GN 2342-E-1**: with AISI 316 LHC fusion stainless steel retaining washer with eyelet.
- **GN 2342-E-2**: with AISI 316 LHC fusion stainless steel retaining washer with eyelet, and transversal hole for GN 1024 spring cotter pins.
- **GN 2342-L-1**: with AISI 316 LHC sintered stainless steel slotted retaining washer.

FEATURES AND APPLICATIONS

Three types of pins are available depending on the requirements:


- GN 2342-B: for normal use with locking function;
- GN 2342-E: for use with spring cotter pins GN 1024 (see page 1043) which can be retained by means of retaining cables GN 111.2 (see page 935);
- GN 2342-L: clamping by means of countersunk head screws with the function of preventing loss and rotation.

The executions with suffix 2 have a transversal hole for the use of GN 1024 spring cotter pins, so as to avoid accidental loss of the pin.

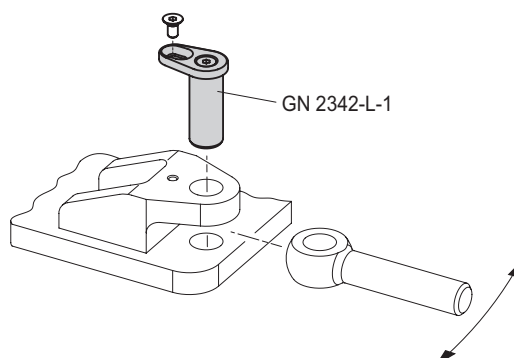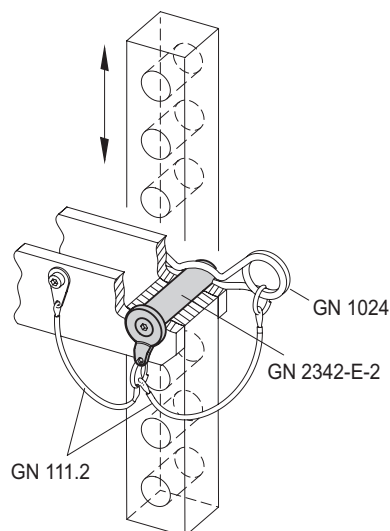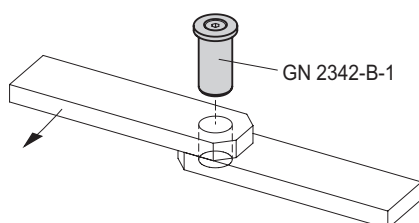

Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
8	0.31
10	0.39
12	0.47
16	0.63
20	0.79


GN 2342-B-1

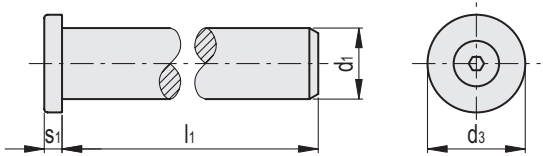


INOX STAINLESS STEEL METRIC

GN 2342-B-1

Code	Description	d1 h9	d3	l1	s1	
GN.71101	GN 2342-NI-8-16-B-1	8	12	16	3	10
GN.71111	GN 2342-NI-8-20-B-1	8	12	20	3	11
GN.71121	GN 2342-NI-8-24-B-1	8	12	24	3	13
GN.71131	GN 2342-NI-8-28-B-1	8	12	28	3	14
GN.71141	GN 2342-NI-8-30-B-1	8	12	30	3	15
GN.71151	GN 2342-NI-8-32-B-1	8	12	32	3	16
GN.71161	GN 2342-NI-8-35-B-1	8	12	35	3	17
GN.71171	GN 2342-NI-8-40-B-1	8	12	40	3	19
GN.71181	GN 2342-NI-8-45-B-1	8	12	45	3	21
GN.71191	GN 2342-NI-8-50-B-1	8	12	50	3	23
GN.71201	GN 2342-NI-8-55-B-1	8	12	55	3	25
GN.71211	GN 2342-NI-8-60-B-1	8	12	60	3	27
GN.71231	GN 2342-NI-10-20-B-1	10	15	20	3	17
GN.71241	GN 2342-NI-10-24-B-1	10	15	24	3	19
GN.71251	GN 2342-NI-10-30-B-1	10	15	30	3	23
GN.71261	GN 2342-NI-10-35-B-1	10	15	35	3	26
GN.71271	GN 2342-NI-10-40-B-1	10	15	40	3	29
GN.71281	GN 2342-NI-10-45-B-1	10	15	45	3	32
GN.71291	GN 2342-NI-10-50-B-1	10	15	50	3	36
GN.71301	GN 2342-NI-10-55-B-1	10	15	55	3	39
GN.71311	GN 2342-NI-10-60-B-1	10	15	60	3	42
GN.71321	GN 2342-NI-10-65-B-1	10	15	65	3	45
GN.71331	GN 2342-NI-10-70-B-1	10	15	70	3	48
GN.71341	GN 2342-NI-10-80-B-1	10	15	80	3	54
GN.71361	GN 2342-NI-12-20-B-1	12	17	20	4	25
GN.71371	GN 2342-NI-12-24-B-1	12	17	24	4	29
GN.71381	GN 2342-NI-12-30-B-1	12	17	30	4	34
GN.71391	GN 2342-NI-12-35-B-1	12	17	35	4	45
GN.71401	GN 2342-NI-12-40-B-1	12	17	40	4	42
GN.71411	GN 2342-NI-12-45-B-1	12	17	45	4	47
GN.71421	GN 2342-NI-12-50-B-1	12	17	50	4	51
GN.71431	GN 2342-NI-12-55-B-1	12	17	55	4	56
GN.71441	GN 2342-NI-12-60-B-1	12	17	60	4	61
GN.71451	GN 2342-NI-12-65-B-1	12	17	65	4	65
GN.71461	GN 2342-NI-12-70-B-1	12	17	70	4	70
GN.71471	GN 2342-NI-12-80-B-1	12	17	80	4	78
GN.71501	GN 2342-NI-16-32-B-1	16	22	32	4	62
GN.71511	GN 2342-NI-16-35-B-1	16	22	35	4	67
GN.71521	GN 2342-NI-16-40-B-1	16	22	40	4	74
GN.71531	GN 2342-NI-16-45-B-1	16	22	45	4	82
GN.71541	GN 2342-NI-16-50-B-1	16	22	50	4	90
GN.71551	GN 2342-NI-16-55-B-1	16	22	55	4	98
GN.71561	GN 2342-NI-16-60-B-1	16	22	60	4	106
GN.71571	GN 2342-NI-16-65-B-1	16	22	65	4	114
GN.71581	GN 2342-NI-16-70-B-1	16	22	70	4	122
GN.71591	GN 2342-NI-16-80-B-1	16	22	80	4	138
GN.71601	GN 2342-NI-16-90-B-1	16	22	90	4	154
GN.71611	GN 2342-NI-16-100-B-1	16	22	100	4	170
GN.71631	GN 2342-NI-20-40-B-1	20	26	40	4	115
GN.71641	GN 2342-NI-20-45-B-1	20	26	45	4	126
GN.71651	GN 2342-NI-20-50-B-1	20	26	50	4	138
GN.71661	GN 2342-NI-20-55-B-1	20	26	55	4	150
GN.71671	GN 2342-NI-20-60-B-1	20	26	60	4	163
GN.71681	GN 2342-NI-20-65-B-1	20	26	65	4	175
GN.71691	GN 2342-NI-20-70-B-1	20	26	70	4	188
GN.71701	GN 2342-NI-20-80-B-1	20	26	80	4	212
GN.71711	GN 2342-NI-20-90-B-1	20	26	90	4	237
GN.71621	GN 2342-NI-20-100-B-1	20	26	100	4	262

 


Indexing and positioning elements

 

Indexing and positioning elements

Conversion Table	
1 mm = 0,039 inch	
d1	
mm	inch
8	0.31
10	0.39
12	0.47
16	0.63
20	0.79

GN 2342-B-2

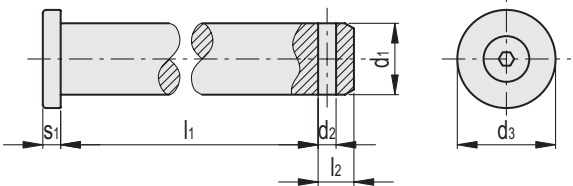


GN 2342-B-2

INOX STAINLESS STEEL METRIC

Code	Description	d1 h9	d2	d3	l1	l2	s1	d2	⚖
								Spring cotter pins	
GN.71103	GN 2342-NI-8-16-B-2	8	2.5	12	16	5.5	3	GN 1024-NI-2-D	12
GN.71113	GN 2342-NI-8-20-B-2	8	2.5	12	20	5.5	3	GN 1024-NI-2-D	13
GN.71123	GN 2342-NI-8-24-B-2	8	2.5	12	24	5.5	3	GN 1024-NI-2-D	15
GN.71133	GN 2342-NI-8-28-B-2	8	2.5	12	28	5.5	3	GN 1024-NI-2-D	16
GN.71143	GN 2342-NI-8-30-B-2	8	2.5	12	30	5.5	3	GN 1024-NI-2-D	17
GN.71153	GN 2342-NI-8-32-B-2	8	2.5	12	32	5.5	3	GN 1024-NI-2-D	18
GN.71163	GN 2342-NI-8-35-B-2	8	2.5	12	35	5.5	3	GN 1024-NI-2-D	19
GN.71173	GN 2342-NI-8-40-B-2	8	2.5	12	40	5.5	3	GN 1024-NI-2-D	21
GN.71183	GN 2342-NI-8-45-B-2	8	2.5	12	45	5.5	3	GN 1024-NI-2-D	12
GN.71193	GN 2342-NI-8-50-B-2	8	2.5	12	50	5.5	3	GN 1024-NI-2-D	25
GN.71203	GN 2342-NI-8-55-B-2	8	2.5	12	55	5.5	3	GN 1024-NI-2-D	27
GN.71213	GN 2342-NI-8-60-B-2	8	2.5	12	60	5.5	3	GN 1024-NI-2-D	29
GN.71233	GN 2342-NI-10-20-B-2	10	2.5	15	20	6	3	GN 1024-NI-2-E / -D	21
GN.71243	GN 2342-NI-10-24-B-2	10	2.5	15	24	6	3	GN 1024-NI-2-E / -D	23
GN.71253	GN 2342-NI-10-30-B-2	10	2.5	15	30	6	3	GN 1024-NI-2-E / -D	27
GN.71263	GN 2342-NI-10-35-B-2	10	2.5	15	35	6	3	GN 1024-NI-2-E / -D	30
GN.71273	GN 2342-NI-10-40-B-2	10	2.5	15	40	6	3	GN 1024-NI-2-E / -D	33
GN.71283	GN 2342-NI-10-45-B-2	10	2.5	15	45	6	3	GN 1024-NI-2-E / -D	36
GN.71293	GN 2342-NI-10-50-B-2	10	2.5	15	50	6	3	GN 1024-NI-2-E / -D	39
GN.71303	GN 2342-NI-10-55-B-2	10	2.5	15	55	6	3	GN 1024-NI-2-E / -D	42
GN.71313	GN 2342-NI-10-60-B-2	10	2.5	15	60	6	3	GN 1024-NI-2-E / -D	44
GN.71323	GN 2342-NI-10-65-B-2	10	2.5	15	65	6	3	GN 1024-NI-2-E / -D	48
GN.71333	GN 2342-NI-10-70-B-2	10	2.5	15	70	6	3	GN 1024-NI-2-E / -D	51
GN.71343	GN 2342-NI-10-80-B-2	10	2.5	15	80	6	3	GN 1024-NI-2-E / -D	58
GN.71363	GN 2342-NI-12-20-B-2	12	2.5	17	20	7	4	GN 1024-NI-2-E / -D	30
GN.71373	GN 2342-NI-12-24-B-2	12	2.5	17	24	7	4	GN 1024-NI-2-E / -D	34
GN.71383	GN 2342-NI-12-30-B-2	12	2.5	17	30	7	4	GN 1024-NI-2-E / -D	39
GN.71393	GN 2342-NI-12-35-B-2	12	2.5	17	35	7	4	GN 1024-NI-2-E / -D	44
GN.71403	GN 2342-NI-12-40-B-2	12	2.5	17	40	7	4	GN 1024-NI-2-E / -D	48
GN.71413	GN 2342-NI-12-45-B-2	12	2.5	17	45	7	4	GN 1024-NI-2-E / -D	53
GN.71423	GN 2342-NI-12-50-B-2	12	2.5	17	50	7	4	GN 1024-NI-2-E / -D	57
GN.71433	GN 2342-NI-12-55-B-2	12	2.5	17	55	7	4	GN 1024-NI-2-E / -D	61
GN.71443	GN 2342-NI-12-60-B-2	12	2.5	17	60	7	4	GN 1024-NI-2-E / -D	66
GN.71453	GN 2342-NI-12-65-B-2	12	2.5	17	65	7	4	GN 1024-NI-2-E / -D	70
GN.71463	GN 2342-NI-12-70-B-2	12	2.5	17	70	7	4	GN 1024-NI-2-E / -D	75
GN.71473	GN 2342-NI-12-80-B-2	12	2.5	17	80	7	4	GN 1024-NI-2-E / -D	84
GN.71503	GN 2342-NI-16-32-B-2	16	3.5	22	32	8	4	GN 1024-NI-3-E / -D	73
GN.71513	GN 2342-NI-16-35-B-2	16	3.5	22	35	8	4	GN 1024-NI-3-E / -D	77
GN.71523	GN 2342-NI-16-40-B-2	16	3.5	22	40	8	4	GN 1024-NI-3-E / -D	85
GN.71533	GN 2342-NI-16-45-B-2	16	3.5	22	45	8	4	GN 1024-NI-3-E / -D	93
GN.71543	GN 2342-NI-16-50-B-2	16	3.5	22	50	8	4	GN 1024-NI-3-E / -D	101
GN.71553	GN 2342-NI-16-55-B-2	16	3.5	22	55	8	4	GN 1024-NI-3-E / -D	109
GN.71563	GN 2342-NI-16-60-B-2	16	3.5	22	60	8	4	GN 1024-NI-3-E / -D	117
GN.71573	GN 2342-NI-16-65-B-2	16	3.5	22	65	8	4	GN 1024-NI-3-E / -D	125
GN.71583	GN 2342-NI-16-70-B-2	16	3.5	22	70	8	4	GN 1024-NI-3-E / -D	133
GN.71593	GN 2342-NI-16-80-B-2	16	3.5	22	80	8	4	GN 1024-NI-3-E / -D	149
GN.71603	GN 2342-NI-16-90-B-2	16	3.5	22	90	8	4	GN 1024-NI-3-E / -D	165
GN.71613	GN 2342-NI-16-100-B-2	16	3.5	22	100	8	4	GN 1024-NI-3-E / -D	180
GN.71633	GN 2342-NI-20-40-B-2	20	4.5	26	40	10.5	4	GN 1024-NI-4-E / -D	136
GN.71643	GN 2342-NI-20-45-B-2	20	4.5	26	45	10.5	4	GN 1024-NI-4-E / -D	158
GN.71653	GN 2342-NI-20-50-B-2	20	4.5	26	50	10.5	4	GN 1024-NI-4-E / -D	161
GN.71663	GN 2342-NI-20-55-B-2	20	4.5	26	55	10.5	4	GN 1024-NI-4-E / -D	173
GN.71673	GN 2342-NI-20-60-B-2	20	4.5	26	60	10.5	4	GN 1024-NI-4-E / -D	186
GN.71683	GN 2342-NI-20-65-B-2	20	4.5	26	65	10.5	4	GN 1024-NI-4-E / -D	198
GN.71693	GN 2342-NI-20-70-B-2	20	4.5	26	70	10.5	4	GN 1024-NI-4-E / -D	211
GN.71703	GN 2342-NI-20-80-B-2	20	4.5	26	80	10.5	4	GN 1024-NI-4-E / -D	235
GN.71713	GN 2342-NI-20-90-B-2	20	4.5	26	90	10.5	4	GN 1024-NI-4-E / -D	260
GN.71623	GN 2342-NI-20-100-B-2	20	4.5	26	100	10.5	4	GN 1024-NI-4-E / -D	287

GN 2342-E-1

Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
8	0.31
10	0.39
12	0.47
16	0.63
20	0.79

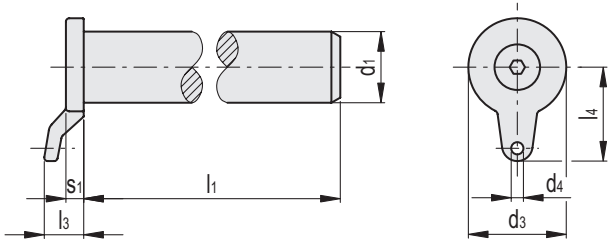

INOX STAINLESS STEEL METRIC

GN 2342-E-1

Code	Description	d1 H9	d3	d4	l1	l3	l4	s1	d4 Retaining cables	
GN.71105	GN 2342-NI-8-16-E-1	8	12	2.5	16	7	13.5	3	GN 111.2-...-14	10
GN.71115	GN 2342-NI-8-20-E-1	8	12	2.5	20	7	13.5	3	GN 111.2-...-14	12
GN.71125	GN 2342-NI-8-24-E-1	8	12	2.5	24	7	13.5	3	GN 111.2-...-14	13
GN.71135	GN 2342-NI-8-28-E-1	8	12	2.5	28	7	13.5	3	GN 111.2-...-14	15
GN.71145	GN 2342-NI-8-30-E-1	8	12	2.5	30	7	13.5	3	GN 111.2-...-14	16
GN.71155	GN 2342-NI-8-32-E-1	8	12	2.5	32	7	13.5	3	GN 111.2-...-14	17
GN.71165	GN 2342-NI-8-35-E-1	8	12	2.5	35	7	13.5	3	GN 111.2-...-14	18
GN.71175	GN 2342-NI-8-40-E-1	8	12	2.5	40	7	13.5	3	GN 111.2-...-14	20
GN.71185	GN 2342-NI-8-45-E-1	8	12	2.5	45	7	13.5	3	GN 111.2-...-14	22
GN.71195	GN 2342-NI-8-50-E-1	8	12	2.5	50	7	13.5	3	GN 111.2-...-14	24
GN.71205	GN 2342-NI-8-55-E-1	8	12	2.5	55	7	13.5	3	GN 111.2-...-14	26
GN.71215	GN 2342-NI-8-60-E-1	8	12	2.5	60	7	13.5	3	GN 111.2-...-14	28
GN.71235	GN 2342-NI-10-20-E-1	10	15	2.5	20	7	15	3	GN 111.2-...-14	18
GN.71245	GN 2342-NI-10-24-E-1	10	15	2.5	24	7	15	3	GN 111.2-...-14	20
GN.71255	GN 2342-NI-10-30-E-1	10	15	2.5	30	7	15	3	GN 111.2-...-14	24
GN.71265	GN 2342-NI-10-35-E-1	10	15	2.5	35	7	15	3	GN 111.2-...-14	27
GN.71275	GN 2342-NI-10-40-E-1	10	15	2.5	40	7	15	3	GN 111.2-...-14	30
GN.71285	GN 2342-NI-10-45-E-1	10	15	2.5	45	7	15	3	GN 111.2-...-14	33
GN.71295	GN 2342-NI-10-50-E-1	10	15	2.5	50	7	15	3	GN 111.2-...-14	36
GN.71305	GN 2342-NI-10-55-E-1	10	15	2.5	55	7	15	3	GN 111.2-...-14	39
GN.71315	GN 2342-NI-10-60-E-1	10	15	2.5	60	7	15	3	GN 111.2-...-14	43
GN.71325	GN 2342-NI-10-65-E-1	10	15	2.5	65	7	15	3	GN 111.2-...-14	47
GN.71335	GN 2342-NI-10-70-E-1	10	15	2.5	70	7	15	3	GN 111.2-...-14	49
GN.71345	GN 2342-NI-10-80-E-1	10	15	2.5	80	7	15	3	GN 111.2-...-14	55
GN.71365	GN 2342-NI-12-20-E-1	12	17	3	20	9	18.5	4	GN 111.2-...-14 / -18	27
GN.71375	GN 2342-NI-12-24-E-1	12	17	3	24	9	18.5	4	GN 111.2-...-14 / -18	30
GN.71385	GN 2342-NI-12-30-E-1	12	17	3	30	9	18.5	4	GN 111.2-...-14 / -18	36
GN.71395	GN 2342-NI-12-35-E-1	12	17	3	35	9	18.5	4	GN 111.2-...-14 / -18	45
GN.71405	GN 2342-NI-12-40-E-1	12	17	3	40	9	18.5	4	GN 111.2-...-14 / -18	45
GN.71415	GN 2342-NI-12-45-E-1	12	17	3	45	9	18.5	4	GN 111.2-...-14 / -18	49
GN.71425	GN 2342-NI-12-50-E-1	12	17	3	50	9	18.5	4	GN 111.2-...-14 / -18	53
GN.71435	GN 2342-NI-12-55-E-1	12	17	3	55	9	18.5	4	GN 111.2-...-14 / -18	58
GN.71445	GN 2342-NI-12-60-E-1	12	17	3	60	9	18.5	4	GN 111.2-...-14 / -18	62
GN.71455	GN 2342-NI-12-65-E-1	12	17	3	65	9	18.5	4	GN 111.2-...-14 / -18	67
GN.71465	GN 2342-NI-12-70-E-1	12	17	3	70	9	18.5	4	GN 111.2-...-14 / -18	71
GN.71475	GN 2342-NI-12-80-E-1	12	17	3	80	9	18.5	4	GN 111.2-...-14 / -18	80
GN.71505	GN 2342-NI-16-32-E-1	16	22	3	32	9	21	4	GN 111.2-...-14 / -18	63
GN.71515	GN 2342-NI-16-35-E-1	16	22	3	35	9	21	4	GN 111.2-...-14 / -18	68
GN.71525	GN 2342-NI-16-40-E-1	16	22	3	40	9	21	4	GN 111.2-...-14 / -18	76
GN.71535	GN 2342-NI-16-45-E-1	16	22	3	45	9	21	4	GN 111.2-...-14 / -18	84
GN.71545	GN 2342-NI-16-50-E-1	16	22	3	50	9	21	4	GN 111.2-...-14 / -18	92
GN.71555	GN 2342-NI-16-55-E-1	16	22	3	55	9	21	4	GN 111.2-...-14 / -18	100
GN.71565	GN 2342-NI-16-60-E-1	16	22	3	60	9	21	4	GN 111.2-...-14 / -18	108
GN.71575	GN 2342-NI-16-65-E-1	16	22	3	65	9	21	4	GN 111.2-...-14 / -18	115
GN.71585	GN 2342-NI-16-70-E-1	16	22	3	70	9	21	4	GN 111.2-...-14 / -18	123
GN.71595	GN 2342-NI-16-80-E-1	16	22	3	80	9	21	4	GN 111.2-...-14 / -18	139
GN.71605	GN 2342-NI-16-90-E-1	16	22	3	90	9	21	4	GN 111.2-...-14 / -18	155
GN.71615	GN 2342-NI-16-100-E-1	16	22	3	100	9	21	4	GN 111.2-...-14 / -18	171
GN.71635	GN 2342-NI-20-40-E-1	20	26	3.5	40	9	24	4	GN 111.2-...-14 / -18 / -24	115
GN.71645	GN 2342-NI-20-45-E-1	20	26	3.5	45	9	24	4	GN 111.2-...-14 / -18 / -24	128
GN.71655	GN 2342-NI-20-50-E-1	20	26	3.5	50	9	24	4	GN 111.2-...-14 / -18 / -24	140
GN.71665	GN 2342-NI-20-55-E-1	20	26	3.5	55	9	24	4	GN 111.2-...-14 / -18 / -24	152
GN.71675	GN 2342-NI-20-60-E-1	20	26	3.5	60	9	24	4	GN 111.2-...-14 / -18 / -24	165
GN.71685	GN 2342-NI-20-65-E-1	20	26	3.5	65	9	24	4	GN 111.2-...-14 / -18 / -24	177
GN.71695	GN 2342-NI-20-70-E-1	20	26	3.5	70	9	24	4	GN 111.2-...-14 / -18 / -24	190
GN.71705	GN 2342-NI-20-80-E-1	20	26	3.5	80	9	24	4	GN 111.2-...-14 / -18 / -24	214
GN.71715	GN 2342-NI-20-90-E-1	20	26	3.5	90	9	24	4	GN 111.2-...-14 / -18 / -24	239
GN.71625	GN 2342-NI-20-100-E-1	20	26	3.5	100	9	24	4	GN 111.2-...-14 / -18 / -24	264




Indexing and positioning elements



GN 2342-E-2

Conversion Table 1 mm = 0.039 inch	
mm	inch
8	0.31
10	0.39
12	0.47
16	0.63
20	0.79

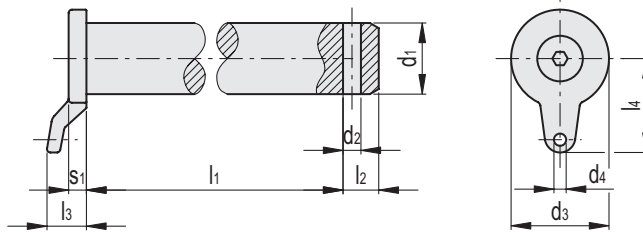


INOX STAINLESS STEEL METRIC

GN 2342-E-2

Code	Description	d1 h9	d2	d3	d4	l1	l2	l3	l4	s1	d2 Spring cotter pins	d4 Retaining cables	
GN.71107	GN 2342-NI-8-16-E-2	8	2.5	12	2.5	16	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	12
GN.71117	GN 2342-NI-8-20-E-2	8	2.5	12	2.5	20	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	14
GN.71127	GN 2342-NI-8-24-E-2	8	2.5	12	2.5	24	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	15
GN.71137	GN 2342-NI-8-28-E-2	8	2.5	12	2.5	28	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	17
GN.71147	GN 2342-NI-8-30-E-2	8	2.5	12	2.5	30	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	16
GN.71157	GN 2342-NI-8-32-E-2	8	2.5	12	2.5	32	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	18
GN.71167	GN 2342-NI-8-35-E-2	8	2.5	12	2.5	35	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	20
GN.71177	GN 2342-NI-8-40-E-2	8	2.5	12	2.5	40	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	22
GN.71187	GN 2342-NI-8-45-E-2	8	2.5	12	2.5	45	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	24
GN.71197	GN 2342-NI-8-50-E-2	8	2.5	12	2.5	50	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	26
GN.71207	GN 2342-NI-8-55-E-2	8	2.5	12	2.5	55	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	27
GN.71217	GN 2342-NI-8-60-E-2	8	2.5	12	2.5	60	5.5	7	13.5	3	GN 1024-NI-2-D	GN 111.2-...-14	29
GN.71237	GN 2342-NI-10-20-E-2	10	2.5	15	2.5	20	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	21
GN.71247	GN 2342-NI-10-24-E-2	10	2.5	15	2.5	24	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	24
GN.71257	GN 2342-NI-10-30-E-2	10	2.5	15	2.5	30	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	27
GN.71267	GN 2342-NI-10-35-E-2	10	2.5	15	2.5	35	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	30
GN.71277	GN 2342-NI-10-40-E-2	10	2.5	15	2.5	40	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	34
GN.71287	GN 2342-NI-10-45-E-2	10	2.5	15	2.5	45	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	37
GN.71297	GN 2342-NI-10-50-E-2	10	2.5	15	2.5	50	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	40
GN.71307	GN 2342-NI-10-55-E-2	10	2.5	15	2.5	55	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	43
GN.71317	GN 2342-NI-10-60-E-2	10	2.5	15	2.5	60	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	46
GN.71327	GN 2342-NI-10-65-E-2	10	2.5	15	2.5	65	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	49
GN.71337	GN 2342-NI-10-70-E-2	10	2.5	15	2.5	70	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	52
GN.71347	GN 2342-NI-10-80-E-2	10	2.5	15	2.5	80	6	7	15	3	GN 1024-NI-2-E / -D	GN 111.2-...-14	58
GN.71367	GN 2342-NI-12-20-E-2	12	2.5	17	3	20	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	32
GN.71377	GN 2342-NI-12-24-E-2	12	2.5	17	3	24	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	36
GN.71387	GN 2342-NI-12-30-E-2	12	2.5	17	3	30	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	41
GN.71397	GN 2342-NI-12-35-E-2	12	2.5	17	3	35	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	45
GN.71407	GN 2342-NI-12-40-E-2	12	2.5	17	3	40	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	50
GN.71417	GN 2342-NI-12-45-E-2	12	2.5	17	3	45	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	54
GN.71427	GN 2342-NI-12-50-E-2	12	2.5	17	3	50	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	59
GN.71437	GN 2342-NI-12-55-E-2	12	2.5	17	3	55	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	63
GN.71447	GN 2342-NI-12-60-E-2	12	2.5	17	3	60	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	68
GN.71457	GN 2342-NI-12-65-E-2	12	2.5	17	3	65	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	72
GN.71467	GN 2342-NI-12-70-E-2	12	2.5	17	3	70	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	76
GN.71477	GN 2342-NI-12-80-E-2	12	2.5	17	3	80	7	9	18.5	4	GN 1024-NI-2-E / -D	GN 111.2-...-14 / -18	84
GN.71507	GN 2342-NI-16-32-E-2	16	3.5	22	3	32	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	74
GN.71517	GN 2342-NI-16-35-E-2	16	3.5	22	3	35	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	79
GN.71527	GN 2342-NI-16-40-E-2	16	3.5	22	3	40	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	87
GN.71537	GN 2342-NI-16-45-E-2	16	3.5	22	3	45	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	95
GN.71547	GN 2342-NI-16-50-E-2	16	3.5	22	3	50	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	103
GN.71557	GN 2342-NI-16-55-E-2	16	3.5	22	3	55	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	110
GN.71567	GN 2342-NI-16-60-E-2	16	3.5	22	3	60	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	119
GN.71577	GN 2342-NI-16-65-E-2	16	3.5	22	3	65	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	126
GN.71587	GN 2342-NI-16-70-E-2	16	3.5	22	3	70	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	135
GN.71597	GN 2342-NI-16-80-E-2	16	3.5	22	3	80	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	150
GN.71607	GN 2342-NI-16-90-E-2	16	3.5	22	3	90	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	166
GN.71617	GN 2342-NI-16-100-E-2	16	3.5	22	3	100	8	9	21	4	GN 1024-NI-3-E / -D	GN 111.2-...-14 / -18	182
GN.71637	GN 2342-NI-20-40-E-2	20	4.5	26	3.5	40	10.5	9	24	4	GN 1024-NI-4-E / -D	GN 111.2-...-14 / -18 / -24	138
GN.71647	GN 2342-NI-20-45-E-2	20	4.5	26	3.5	45	10.5	9	24	4	GN 1024-NI-4-E / -D	GN 111.2-...-14 / -18 / -24	160
GN.71657	GN 2342-NI-20-50-E-2	20	4.5	26	3.5	50	10.5	9	24	4	GN 1024-NI-4-E / -D	GN 111.2-...-14 / -18 / -24	163
GN.71667	GN 2342-NI-20-55-E-2	20	4.5	26	3.5	55	10.5	9	24	4	GN 1024-NI-4-E / -D	GN 111.2-...-14 / -18 / -24	175
GN.71677	GN 2342-NI-20-60-E-2	20	4.5	26	3.5	60	10.5	9	24	4	GN 1024-NI-4-E / -D	GN 111.2-...-14 / -18 / -24	187
GN.71687	GN 2342-NI-20-65-E-2	20	4.5	26	3.5	65	10.5	9	24	4	GN 1024-NI-4-E / -D	GN 111.2-...-14 / -18 / -24	200
GN.71697	GN 2342-NI-20-70-E-2	20	4.5	26	3.5	70	10.5	9	24	4	GN 1024-NI-4-E / -D	GN 111.2-...-14 / -18 / -24	213
GN.71707	GN 2342-NI-20-80-E-2	20	4.5	26	3.5	80	10.5	9	24	4	GN 1024-NI-4-E / -D	GN 111.2-...-14 / -18 / -24	237
GN.71717	GN 2342-NI-20-90-E-2	20	4.5	26	3.5	90	10.5	9	24	4	GN 1024-NI-4-E / -D	GN 111.2-...-14 / -18 / -24	262
GN.71627	GN 2342-NI-20-100-E-2	20	4.5	26	3.5	100	10.5	9	24	4	GN 1024-NI-4-E / -D	GN 111.2-...-14 / -18 / -24	286


Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
8	0.31
10	0.39
12	0.47
16	0.63
20	0.79

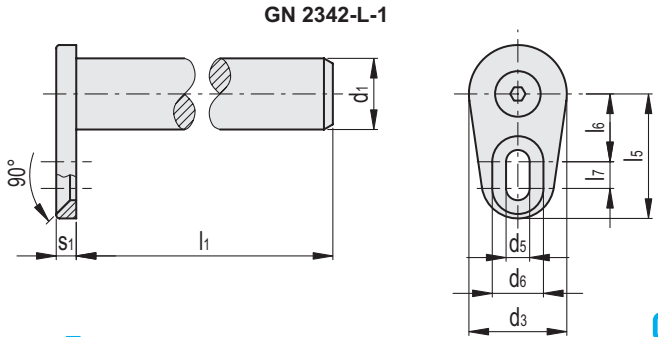

INOX STAINLESS STEEL METRIC

GN 2342-L-1

Code	Description	d1 h9	d3	d5	d6	l1	l5	l6	l7	s1	⚖
GN.71109	GN 2342-NI-8-16-L-1	8	12	4.3	9.2	16	18	10	2	4	13
GN.71119	GN 2342-NI-8-20-L-1	8	12	4.3	9.2	20	18	10	2	4	14
GN.71129	GN 2342-NI-8-24-L-1	8	12	4.3	9.2	24	18	10	2	4	16
GN.71139	GN 2342-NI-8-28-L-1	8	12	4.3	9.2	28	18	10	2	4	18
GN.71149	GN 2342-NI-8-30-L-1	8	12	4.3	9.2	30	18	10	2	4	18
GN.71159	GN 2342-NI-8-32-L-1	8	12	4.3	9.2	32	18	10	2	4	19
GN.71169	GN 2342-NI-8-35-L-1	8	12	4.3	9.2	35	18	10	2	4	20
GN.71179	GN 2342-NI-8-40-L-1	8	12	4.3	9.2	40	18	10	2	4	22
GN.71189	GN 2342-NI-8-45-L-1	8	12	4.3	9.2	45	18	10	2	4	24
GN.71199	GN 2342-NI-8-50-L-1	8	12	4.3	9.2	50	18	10	2	4	26
GN.71209	GN 2342-NI-8-55-L-1	8	12	4.3	9.2	55	18	10	2	4	28
GN.71219	GN 2342-NI-8-60-L-1	8	12	4.3	9.2	60	18	10	2	4	30
GN.71239	GN 2342-NI-10-20-L-1	10	15	4.3	9.2	20	21	11	4	4	21
GN.71249	GN 2342-NI-10-24-L-1	10	15	4.3	9.2	24	21	11	4	4	24
GN.71259	GN 2342-NI-10-30-L-1	10	15	4.3	9.2	30	21	11	4	4	27
GN.71269	GN 2342-NI-10-35-L-1	10	15	4.3	9.2	35	21	11	4	4	30
GN.71279	GN 2342-NI-10-40-L-1	10	15	4.3	9.2	40	21	11	4	4	34
GN.71289	GN 2342-NI-10-45-L-1	10	15	4.3	9.2	45	21	11	4	4	37
GN.71299	GN 2342-NI-10-50-L-1	10	15	4.3	9.2	50	21	11	4	4	43
GN.71309	GN 2342-NI-10-55-L-1	10	15	4.3	9.2	55	21	11	4	4	40
GN.71319	GN 2342-NI-10-60-L-1	10	15	4.3	9.2	60	21	11	4	4	46
GN.71329	GN 2342-NI-10-65-L-1	10	15	4.3	9.2	65	21	11	4	4	49
GN.71339	GN 2342-NI-10-70-L-1	10	15	4.3	9.2	70	21	11	4	4	52
GN.71349	GN 2342-NI-10-80-L-1	10	15	4.3	9.2	80	21	11	4	4	58
GN.71369	GN 2342-NI-12-20-L-1	12	17	5.3	11.5	20	23	12	4	4.5	35
GN.71379	GN 2342-NI-12-24-L-1	12	17	5.3	11.5	24	23	12	4	4.5	33
GN.71389	GN 2342-NI-12-30-L-1	12	17	5.3	11.5	30	23	12	4	4.5	39
GN.71399	GN 2342-NI-12-35-L-1	12	17	5.3	11.5	35	23	12	4	4.5	43
GN.71409	GN 2342-NI-12-40-L-1	12	17	5.3	11.5	40	23	12	4	4.5	48
GN.71419	GN 2342-NI-12-45-L-1	12	17	5.3	11.5	45	23	12	4	4.5	53
GN.71429	GN 2342-NI-12-50-L-1	12	17	5.3	11.5	50	23	12	4	4.5	51
GN.71439	GN 2342-NI-12-55-L-1	12	17	5.3	11.5	55	23	12	4	4.5	61
GN.71449	GN 2342-NI-12-60-L-1	12	17	5.3	11.5	60	23	12	4	4.5	65
GN.71459	GN 2342-NI-12-65-L-1	12	17	5.3	11.5	65	23	12	4	4.5	70
GN.71469	GN 2342-NI-12-70-L-1	12	17	5.3	11.5	70	23	12	4	4.5	74
GN.71479	GN 2342-NI-12-80-L-1	12	17	5.3	11.5	80	23	12	4	4.5	83
GN.71509	GN 2342-NI-16-32-L-1	16	22	5.3	11.5	32	28	15	6	4.5	68
GN.71519	GN 2342-NI-16-35-L-1	16	22	5.3	11.5	35	28	15	6	4.5	72
GN.71529	GN 2342-NI-16-40-L-1	16	22	5.3	11.5	40	28	15	6	4.5	80
GN.71539	GN 2342-NI-16-45-L-1	16	22	5.3	11.5	45	28	15	6	4.5	88
GN.71549	GN 2342-NI-16-50-L-1	16	22	5.3	11.5	50	28	15	6	4.5	96
GN.71559	GN 2342-NI-16-55-L-1	16	22	5.3	11.5	55	28	15	6	4.5	106
GN.71569	GN 2342-NI-16-60-L-1	16	22	5.3	11.5	60	28	15	6	4.5	112
GN.71579	GN 2342-NI-16-65-L-1	16	22	5.3	11.5	65	28	15	6	4.5	120
GN.71589	GN 2342-NI-16-70-L-1	16	22	5.3	11.5	70	28	15	6	4.5	128
GN.71599	GN 2342-NI-16-80-L-1	16	22	5.3	11.5	80	28	15	6	4.5	144
GN.71609	GN 2342-NI-16-90-L-1	16	22	5.3	11.5	90	28	15	6	4.5	160
GN.71619	GN 2342-NI-16-100-L-1	16	22	5.3	11.5	100	28	15	6	4.5	176
GN.71639	GN 2342-NI-20-40-L-1	20	26	6.4	13.7	40	31	17	6	5	124
GN.71649	GN 2342-NI-20-45-L-1	20	26	6.4	13.7	45	31	17	6	5	137
GN.71659	GN 2342-NI-20-50-L-1	20	26	6.4	13.7	50	31	17	6	5	149
GN.71669	GN 2342-NI-20-55-L-1	20	26	6.4	13.7	55	31	17	6	5	161
GN.71679	GN 2342-NI-20-60-L-1	20	26	6.4	13.7	60	31	17	6	5	175
GN.71689	GN 2342-NI-20-65-L-1	20	26	6.4	13.7	65	31	17	6	5	186
GN.71699	GN 2342-NI-20-70-L-1	20	26	6.4	13.7	70	31	17	6	5	199
GN.71709	GN 2342-NI-20-80-L-1	20	26	6.4	13.7	80	31	17	6	5	223
GN.71719	GN 2342-NI-20-90-L-1	20	26	6.4	13.7	90	31	17	6	5	248
GN.71629	GN 2342-NI-20-100-L-1	20	26	6.4	13.7	100	31	17	6	5	273

 

Indexing and positioning elements