

MATERIAL
 Polyamide based (PA) technopolymer, black colour, glossy finish.

WINDOW
 Transparent polyamide based (PA-T/AR) technopolymer.

PACKING RING
 NBR synthetic rubber.

STANDARD EXECUTION
HGFT.: with matte anodised aluminium star-shaped contrast screen with red central level point.


MAXIMUM CONTINUOUS WORKING TEMPERATURE
 212°F (100°C) at 3 bar pressure.

NOTE
 For use with fluids containing special additives, please contact ELESa Sales Department.

ACCESSORIES ON REQUEST
 Brass nut type GH. (see page 1746) for fitting to reservoirs with wall thickness smaller than 0.20 (5 mm).



ELESa Original design

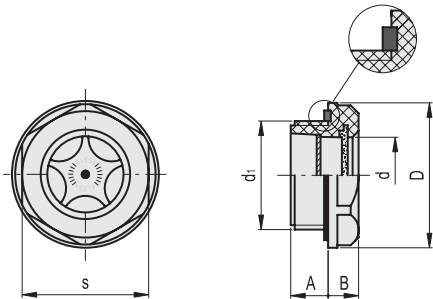

INCH

Code	Description	d1	A	B	D	d	s	Tightening torque [ft·lb]	⚖
914461	HGFT.13-1/2 NPT	1/2 NPT	0.39	0.33	1.1	0.57	0.94	4÷6	0.01
914481	HGFT.16-3/4 NPT	3/4 NPT	0.37	0.33	1.38	0.71	1.26	6÷7	0.02
914521	HGFT.21-1 NPT	1 NPT	0.43	0.37	1.67	0.91	1.5	7÷9	0.03