

STANDARD EXECUTIONS

Base with stainless steel 304 threaded blind ball joint:

- **LMP.F-SST (d)**: without no-slip disk.
- **LMP.F-SST-TR (d)**: with thermoplastic elastomer no-slip coating (TPE)
- **LMP.F-SST-TV (d)**: with vulcanised rubber (NBR) with no-slip coating hardness 70 tolerance +/-5 Shore A.

AISI 304 stainless steel base and nut, AISI 303 stainless steel threaded stem:

- **LMP.F-SST (d – l)**: without no-slip disk.
- **LMP.F-SST-TR (d – l)**: with thermoplastic elastomer no-slip coating (TPE)
- **LMP.F-SST-TV (d – l)**: with vulcanised rubber (NBR) with no-slip coating hardness 70 tolerance +/-5 Shore A.

Base, threaded stem and nut in AISI 316L stainless steel:

- **LMP.F-A4 (d – l)**: without no-slip disk.
- **LMP.F-A4-TR (d – l)**: with thermoplastic elastomer no-slip coating (TPE)
- **LMP.F-A4-TV (d – l)**: with vulcanised rubber (NBR) with no-slip coating hardness 70 tolerance +/-5 Shore A.

SET SCREW

AISI 304 stainless steel.

FEATURES



The resistance of the levelling feet to a static load is obviously limited by the permissible load capacity of the rod (steel strength class 500 N/mm²).

The static load values in the table below are the result of laboratory tests in which the load has been applied perpendicularly to the base.

Such values have to be considered as purely indicative and must be verified under the specific conditions of use.

Under common working conditions, side or angular loading increases the stress on the levelling element and reduces its load capacity.

It's the user's responsibility to determine, case by case, whether the product is suitable for the intended use.

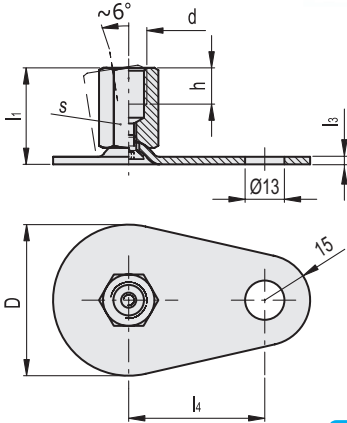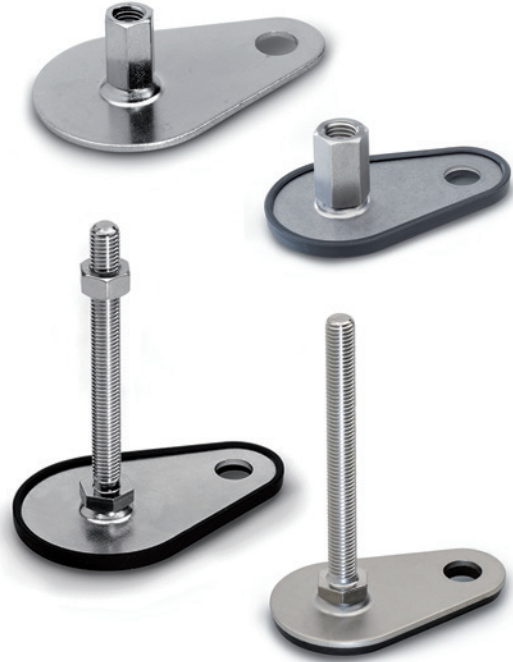


Conversion Table	
1 mm = 0.039 inch	
D	
mm	inch
50	1.97
60	2.36
80	3.15

LMP.F-SST (d)


Code	Description	D	d	l1	l3	l4	h	s	Max. limit static load [N]	⚖️
405131	LMP.F-50-SST-M8	50	M8	25	2.5	45	8	14	8000	90
405132	LMP.F-50-SST-M10	50	M10	28	2.5	45	10	14	14000	90
405133	LMP.F-50-SST-M12	50	M12	32	2.5	45	12	17	14000	119
405134	LMP.F-50-SST-M16	50	M16	37	2.5	45	16	22	14000	125
405190	LMP.F-60-SST-M8	60	M8	25	2.5	50	8	14	8000	110
405191	LMP.F-60-SST-M10	60	M10	28	2.5	50	10	14	14000	110
405192	LMP.F-60-SST-M12	60	M12	32	2.5	50	12	17	16000	170
405193	LMP.F-60-SST-M16	60	M16	37	2.5	50	16	22	16000	500
405249	LMP.F-80-SST-M8	80	M8	26	3	70	8	14	8000	182
405250	LMP.F-80-SST-M10	80	M10	29	3	70	10	14	14000	200
405251	LMP.F-80-SST-M12	80	M12	32	3	70	12	17	20000	220
405252	LMP.F-80-SST-M16	80	M16	38	3	70	16	22	20000	260
405253	LMP.F-80-SST-M20	80	M20	45	3	70	20	27	20000	300

Conversion Table
1 mm = 0.039 inch

mm	inch
50	1.97
60	2.36
80	3.15

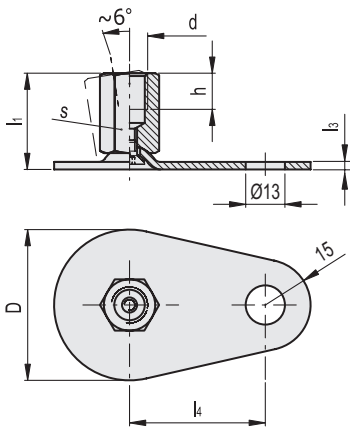

LMP.F-SST-TR

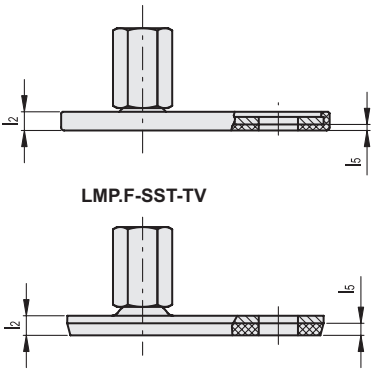


LMP.F-SST-TV

LMP.F-SST-TR (d)


Code	Description	D	d	l1	l2	l3	l4	l5	h	s	Max. limit static load [N]	⚖
405161	LMP.F-50-SST-M8-TR	50	M8	25	6	2.5	45	2	8	14	8000	90
405162	LMP.F-50-SST-M10-TR	50	M10	28	6	2.5	45	2	10	14	14000	90
405163	LMP.F-50-SST-M12-TR	50	M12	32	6	2.5	45	2	12	17	14000	115
405164	LMP.F-50-SST-M16-TR	50	M16	37	6	2.5	45	2	16	22	14000	121
405220	LMP.F-60-SST-M8-TR	60	M8	25	6	2.5	50	2	8	14	8000	110
405221	LMP.F-60-SST-M10-TR	60	M10	28	6	2.5	50	2	10	14	14000	110
405222	LMP.F-60-SST-M12-TR	60	M12	32	6	2.5	50	2	12	17	16000	170
405223	LMP.F-60-SST-M16-TR	60	M16	37	6	2.5	50	2	16	22	16000	180
405284	LMP.F-80-SST-M8-TR	80	M8	26	7	3	70	2	8	14	8000	199
405285	LMP.F-80-SST-M10-TR	80	M10	29	7	3	70	2	10	14	20000	200
405286	LMP.F-80-SST-M12-TR	80	M12	32	7	3	70	2	12	17	20000	220
405287	LMP.F-80-SST-M16-TR	80	M16	38	7	3	70	2	16	22	20000	260
405288	LMP.F-80-SST-M20-TR	80	M20	45	7	3	70	2	20	27	20000	200

LMP.F-SST-TV (d)


Code	Description	D	d	l1	l2	l3	l4	l5	h	s	Max. limit static load [N]	⚖
403781	LMP.F-50-SST-M8-TV	50	M8	25	6.5	2.5	45	4	8	14	8000	90
403782	LMP.F-50-SST-M10-TV	50	M10	28	6.5	2.5	45	4	10	14	14000	94
403779	LMP.F-50-SST-M12-TV	50	M12	32	6.5	2.5	45	4	12	17	14000	119
403780	LMP.F-50-SST-M16-TV	50	M16	37	6.5	2.5	45	4	16	22	14000	125
403801	LMP.F-60-SST-M8-TV	60	M8	25	7	2.5	50	4.5	8	14	8000	110
403802	LMP.F-60-SST-M10-TV	60	M10	28	7	2.5	50	4.5	10	14	14000	120
403803	LMP.F-60-SST-M12-TV	60	M12	32	7	2.5	50	4.5	12	17	16000	170
403799	LMP.F-60-SST-M16-TV	60	M16	37	7	2.5	50	4.5	16	22	16000	170
403820	LMP.F-80-SST-M8-TV	80	M8	26	8	3	70	5	8	14	8000	222
403821	LMP.F-80-SST-M10-TV	80	M10	29	8	3	70	5	10	14	14000	200
403822	LMP.F-80-SST-M12-TV	80	M12	32	8	3	70	5	12	17	20000	220
403823	LMP.F-80-SST-M16-TV	80	M16	38	8	3	70	5	16	22	20000	260
403847	LMP.F-80-SST-M20-TV	80	M20	45	8	3	70	5	20	27	20000	340

 


**LMP.F-SST
LMP.F-A4
(M8, M10, M12)**

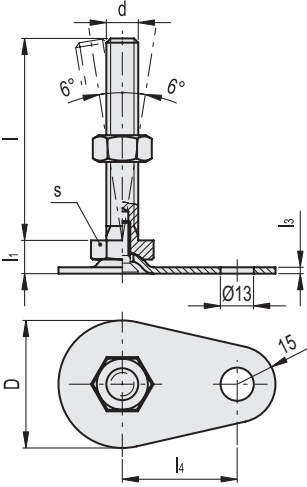

**LMP.F-SST
(M16, M20, M24)**

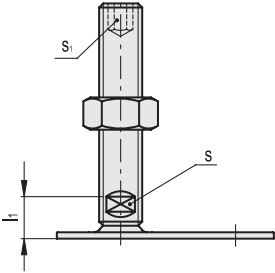

**LMP.F-A4
(M16, M20, M24)**

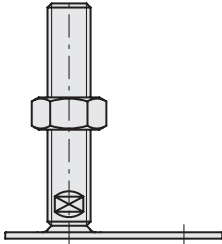

Conversion Table	
1 mm = 0,039 inch	
D	
mm	inch
50	1.97
60	2.36

LMP.F-SST (d - l)

LMP.F-A4 (d - l)

INOX STAINLESS STEEL **METRIC**

Code	Description	Code	Description	D	d	l	l1	l3	l4	s	s1#	Max. limit static load [N]	⚖
405136	LMP.F-50-SST-M8x40	395801	LMP.F-50-A4-M8x40	50	M8	40	11	2.5	45	17	-	8000	61
405137	LMP.F-50-SST-M8x50	395804	LMP.F-50-A4-M8x50	50	M8	50	11	2.5	45	17	-	8000	71
405138	LMP.F-50-SST-M8x63	395807	LMP.F-50-A4-M8x63	50	M8	63	11	2.5	45	17	-	8000	78
405141	LMP.F-50-SST-M10x50	395821	LMP.F-50-A4-M10x50	50	M10	50	11	2.5	45	17	-	14000	81
405142	LMP.F-50-SST-M10x60	395824	LMP.F-50-A4-M10x60	50	M10	60	11	2.5	45	17	-	14000	85
405143	LMP.F-50-SST-M10x80	395827	LMP.F-50-A4-M10x80	50	M10	80	11	2.5	45	17	-	14000	100
405144	LMP.F-50-SST-M10x100	395830	LMP.F-50-A4-M10x100	50	M10	100	11	2.5	45	17	-	14000	101
405146	LMP.F-50-SST-M12x60	395851	LMP.F-50-A4-M12x60	50	M12	60	11	2.5	45	17	-	14000	105
405147	LMP.F-50-SST-M12x80	395854	LMP.F-50-A4-M12x80	50	M12	80	11	2.5	45	17	-	14000	110
405148	LMP.F-50-SST-M12x100	395857	LMP.F-50-A4-M12x100	50	M12	100	11	2.5	45	17	-	14000	121
405149	LMP.F-50-SST-M12x125	395860	LMP.F-50-A4-M12x125	50	M12	125	11	2.5	45	17	-	14000	162
405151	LMP.F-50-SST-M16x75	395881	LMP.F-50-A4-M16x75	50	M16	75	17	2.5	45	12	8	14000	177
405152	LMP.F-50-SST-M16x100	395884	LMP.F-50-A4-M16x100	50	M16	100	17	2.5	45	12	8	14000	202
405153	LMP.F-50-SST-M16x125	395887	LMP.F-50-A4-M16x125	50	M16	125	17	2.5	45	12	8	14000	245
405154	LMP.F-50-SST-M16x150	395890	LMP.F-50-A4-M16x150	50	M16	150	17	2.5	45	12	8	14000	280
405155	LMP.F-50-SST-M16x200	395893	LMP.F-50-A4-M16x200	50	M16	200	17	2.5	45	12	8	14000	361
405196	LMP.F-60-SST-M8x40	395911	LMP.F-60-A4-M8x40	60	M8	40	11	2.5	50	17	-	8000	66
405197	LMP.F-60-SST-M8x50	395914	LMP.F-60-A4-M8x50	60	M8	50	11	2.5	50	17	-	8000	71
405198	LMP.F-60-SST-M8x63	395917	LMP.F-60-A4-M8x63	60	M8	63	11	2.5	50	17	-	8000	83
405201	LMP.F-60-SST-M10x50	395931	LMP.F-60-A4-M10x50	60	M10	50	11	2.5	50	17	-	14000	101
405202	LMP.F-60-SST-M10x60	395934	LMP.F-60-A4-M10x60	60	M10	60	11	2.5	50	17	-	14000	108
405203	LMP.F-60-SST-M10x80	395937	LMP.F-60-A4-M10x80	60	M10	80	11	2.5	50	17	-	14000	115
405204	LMP.F-60-SST-M10x100	395940	LMP.F-60-A4-M10x100	60	M10	100	11	2.5	50	17	-	14000	120
405206	LMP.F-60-SST-M12x60	395961	LMP.F-60-A4-M12x60	60	M12	60	11	2.5	50	17	-	16000	121
405207	LMP.F-60-SST-M12x80	395964	LMP.F-60-A4-M12x80	60	M12	80	11	2.5	50	17	-	16000	137
405208	LMP.F-60-SST-M12x100	395967	LMP.F-60-A4-M12x100	60	M12	100	11	2.5	50	17	-	16000	149
405209	LMP.F-60-SST-M12x125	395970	LMP.F-60-A4-M12x125	60	M12	125	11	2.5	50	17	-	16000	169
405211	LMP.F-60-SST-M16x75	395991	LMP.F-60-A4-M16x75	60	M16	75	17	2.5	50	12	8	16000	189
405212	LMP.F-60-SST-M16x100	395994	LMP.F-60-A4-M16x100	60	M16	100	17	2.5	50	12	8	16000	212
405213	LMP.F-60-SST-M16x125	395997	LMP.F-60-A4-M16x125	60	M16	125	17	2.5	50	12	8	16000	261
405214	LMP.F-60-SST-M16x150	396000	LMP.F-60-A4-M16x150	60	M16	150	17	2.5	50	12	8	16000	303
405210	LMP.F-60-SST-M16x200	396003	LMP.F-60-A4-M16x200	60	M16	200	17	2.5	50	12	8	16000	378




LMP.F-SST (d - l)

LMP.F-A4 (d - l)

INOX STAINLESS STEEL

METRIC

Code	Description	Code	Description	D	d	l	l ₁	l ₃	l ₄	s	s _#	Max. limit static load [N]	
405256	LMP.F-80-SST-M8x40	396101	LMP.F-80-A4-M8x40	80	M8	40	12	3	70	17	-	8000	141
405257	LMP.F-80-SST-M8x50	396104	LMP.F-80-A4-M8x50	80	M8	50	12	3	70	17	-	8000	162
405258	LMP.F-80-SST-M8x63	396107	LMP.F-80-A4-M8x63	80	M8	63	12	3	70	17	-	8000	172
405261	LMP.F-80-SST-M10x50	396121	LMP.F-80-A4-M10x50	80	M10	50	12	3	70	17	-	14000	152
405262	LMP.F-80-SST-M10x60	396124	LMP.F-80-A4-M10x60	80	M10	60	12	3	70	17	-	14000	170
405263	LMP.F-80-SST-M10x80	396127	LMP.F-80-A4-M10x80	80	M10	80	12	3	70	17	-	14000	182
405264	LMP.F-80-SST-M10x100	396130	LMP.F-80-A4-M10x100	80	M10	100	12	3	70	17	-	14000	192
405266	LMP.F-80-SST-M12x60	396151	LMP.F-80-A4-M12x60	80	M12	60	12	3	70	17	-	20000	182
405267	LMP.F-80-SST-M12x80	396154	LMP.F-80-A4-M12x80	80	M12	80	12	3	70	17	-	20000	202
405268	LMP.F-80-SST-M12x100	396157	LMP.F-80-A4-M12x100	80	M12	100	12	3	70	17	-	20000	222
405269	LMP.F-80-SST-M12x125	396160	LMP.F-80-A4-M12x125	80	M12	125	12	3	70	17	-	20000	235
405271	LMP.F-80-SST-M16x75	396181	LMP.F-80-A4-M16x75	80	M16	75	18	3	70	12	8	20000	202
405272	LMP.F-80-SST-M16x100	396184	LMP.F-80-A4-M16x100	80	M16	100	18	3	70	12	8	20000	263
405273	LMP.F-80-SST-M16x125	396187	LMP.F-80-A4-M16x125	80	M16	125	18	3	70	12	8	20000	293
405274	LMP.F-80-SST-M16x150	396190	LMP.F-80-A4-M16x150	80	M16	150	18	3	70	12	8	20000	364
405215	LMP.F-80-SST-M16x200	396193	LMP.F-80-A4-M16x200	80	M16	200	18	3	70	12	8	20000	460
405276	LMP.F-80-SST-M20x75	396211	LMP.F-80-A4-M20x75	80	M20	75	19	3	70	15	10	20000	354
405277	LMP.F-80-SST-M20x100	396214	LMP.F-80-A4-M20x100	80	M20	100	19	3	70	15	10	20000	384
405278	LMP.F-80-SST-M20x125	396217	LMP.F-80-A4-M20x125	80	M20	125	19	3	70	15	10	20000	404
405279	LMP.F-80-SST-M20x150	396220	LMP.F-80-A4-M20x150	80	M20	150	19	3	70	15	10	20000	464
405216	LMP.F-80-SST-M20x200	396223	LMP.F-80-A4-M20x200	80	M20	200	19	3	70	15	10	20000	580
405281	LMP.F-80-SST-M24x100	396241	LMP.F-80-A4-M24x100	80	M24	100	22	3	70	19	12	22000	556
405282	LMP.F-80-SST-M24x125	396244	LMP.F-80-A4-M24x125	80	M24	125	22	3	70	19	12	22000	625
405283	LMP.F-80-SST-M24x150	396247	LMP.F-80-A4-M24x150	80	M24	150	22	3	70	19	12	22000	694
405280	LMP.F-80-SST-M24x200	396250	LMP.F-80-A4-M24x200	80	M24	200	22	3	70	19	12	22000	850

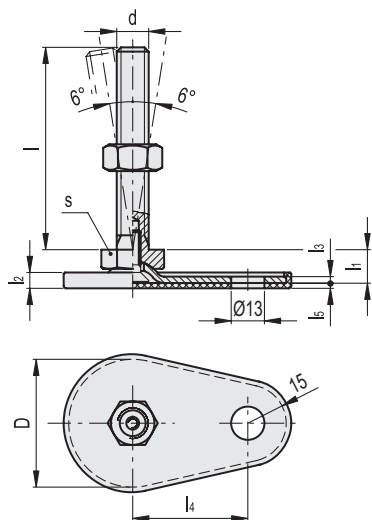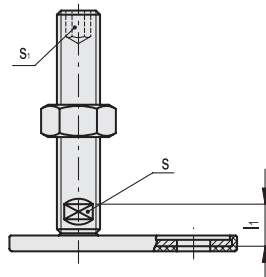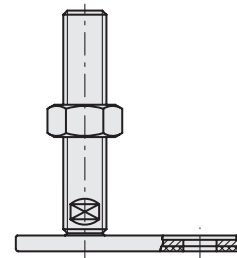LMP.F-SST-TR
LMP.F-A4-TR
(M8, M10, M12)LMP.F-SST-TR
(M16, M20, M24)LMP.F-A4-TR
(M16, M20, M24)

Conversion Table 1 mm = 0.039 inch	
D	
mm	inch
50	1.97
80	3.15

LMP.F-SST-TR (d - l)

LMP.F-A4-TR (d - l)

INOX STAINLESS STEEL

METRIC

Code	Description	Code	Description	D	d	l	l ₁	l ₂	l ₃	l ₄	l ₅	s	s _#	Max. limit static load [N]	
405166	LMP.F-50-SST-M8x40-TR	395802	LMP.F-50-A4-M8x40-TR	50	M8	40	11	6	2.5	45	2	17	-	8000	62
405167	LMP.F-50-SST-M8x50-TR	395805	LMP.F-50-A4-M8x50-TR	50	M8	50	11	6	2.5	45	2	17	-	8000	81
405168	LMP.F-50-SST-M8x63-TR	395808	LMP.F-50-A4-M8x63-TR	50	M8	63	11	6	2.5	45	2	17	-	8000	91
405171	LMP.F-50-SST-M10x50-TR	395822	LMP.F-50-A4-M10x50-TR	50	M10	50	11	6	2.5	45	2	17	-	14000	89
405172	LMP.F-50-SST-M10x60-TR	395825	LMP.F-50-A4-M10x60-TR	50	M10	60	11	6	2.5	45	2	17	-	14000	95
405173	LMP.F-50-SST-M10x80-TR	395828	LMP.F-50-A4-M10x80-TR	50	M10	80	11	6	2.5	45	2	17	-	14000	101
405175	LMP.F-50-SST-M10x100-TR	395831	LMP.F-50-A4-M10x100-TR	50	M10	100	11	6	2.5	45	2	17	-	14000	111

only for LMP.F-SST




LMP.F-SST-TR (d - l)

LMP.F-A4-TR (d - l)

INOX STAINLESS STEEL METRIC

Code	Description	Code	Description	D	d	l	l1	l2	l3	l4	l5	s	s#	Max. limit static load [N]	
405176	LMP.F-50-SST-M12x60-TR	395852	LMP.F-50-A4-M12x60-TR	50	M12	60	11	6	2.5	45	2	17	-	14000	121
405177	LMP.F-50-SST-M12x80-TR	395855	LMP.F-50-A4-M12x80-TR	50	M12	80	11	6	2.5	45	2	17	-	14000	131
405178	LMP.F-50-SST-M12x100-TR	395858	LMP.F-50-A4-M12x100-TR	50	M12	100	11	6	2.5	45	2	17	-	14000	141
405179	LMP.F-50-SST-M12x125-TR	395861	LMP.F-50-A4-M12x125-TR	50	M12	125	11	6	2.5	45	2	17	-	14000	162
405181	LMP.F-50-SST-M16x75-TR	395882	LMP.F-50-A4-M16x75-TR	50	M16	75	17	6	2.5	45	2	12	8	14000	180
405182	LMP.F-50-SST-M16x100-TR	395885	LMP.F-50-A4-M16x100-TR	50	M16	100	17	6	2.5	45	2	12	8	14000	222
405183	LMP.F-50-SST-M16x125-TR	395888	LMP.F-50-A4-M16x125-TR	50	M16	125	17	6	2.5	45	2	12	8	14000	253
405184	LMP.F-50-SST-M16x150-TR	395891	LMP.F-50-A4-M16x150-TR	50	M16	150	17	6	2.5	45	2	12	8	14000	283
405185	LMP.F-50-SST-M16x200-TR	395894	LMP.F-50-A4-M16x200-TR	50	M16	200	17	6	2.5	45	2	12	8	14000	250
405226	LMP.F-60-SST-M8x40-TR	395912	LMP.F-60-A4-M8x40-TR	60	M8	40	11	6	2.5	50	2	17	-	8000	81
405227	LMP.F-60-SST-M8x50-TR	395915	LMP.F-60-A4-M8x50-TR	60	M8	50	11	6	2.5	50	2	17	-	8000	90
405228	LMP.F-60-SST-M8x63-TR	395918	LMP.F-60-A4-M8x63-TR	60	M8	63	11	6	2.5	50	2	17	-	8000	105
405231	LMP.F-60-SST-M10x50-TR	395932	LMP.F-60-A4-M10x50-TR	60	M10	50	11	6	2.5	50	2	17	-	14000	101
405232	LMP.F-60-SST-M10x60-TR	395935	LMP.F-60-A4-M10x60-TR	60	M10	60	11	6	2.5	50	2	17	-	14000	111
405233	LMP.F-60-SST-M10x80-TR	395938	LMP.F-60-A4-M10x80-TR	60	M10	80	11	6	2.5	50	2	17	-	14000	121
405234	LMP.F-60-SST-M10x100-TR	395941	LMP.F-60-A4-M10x100-TR	60	M10	100	11	6	2.5	50	2	17	-	14000	131
405236	LMP.F-60-SST-M12x60-TR	395962	LMP.F-60-A4-M12x60-TR	60	M12	60	11	6	2.5	50	2	17	-	16000	126
405237	LMP.F-60-SST-M12x80-TR	395965	LMP.F-60-A4-M12x80-TR	60	M12	80	11	6	2.5	50	2	17	-	16000	145
405238	LMP.F-60-SST-M12x100-TR	395968	LMP.F-60-A4-M12x100-TR	60	M12	100	11	6	2.5	50	2	17	-	16000	160
405239	LMP.F-60-SST-M12x125-TR	395971	LMP.F-60-A4-M12x125-TR	60	M12	125	11	6	2.5	50	2	17	-	16000	182
405241	LMP.F-60-SST-M16x75-TR	395992	LMP.F-60-A4-M16x75-TR	60	M16	75	17	6	2.5	50	2	12	8	16000	202
405242	LMP.F-60-SST-M16x100-TR	395995	LMP.F-60-A4-M16x100-TR	60	M16	100	17	6	2.5	50	2	12	8	16000	222
405243	LMP.F-60-SST-M16x125-TR	395998	LMP.F-60-A4-M16x125-TR	60	M16	125	17	6	2.5	50	2	12	8	16000	263
405244	LMP.F-60-SST-M16x150-TR	396001	LMP.F-60-A4-M16x150-TR	60	M16	150	17	6	2.5	50	2	12	8	16000	303
405245	LMP.F-60-SST-M16x200-TR	396004	LMP.F-60-A4-M16x200-TR	60	M16	200	17	6	2.5	50	2	12	8	16000	420
405291	LMP.F-80-SST-M8x40-TR	396102	LMP.F-80-A4-M8x40-TR	80	M8	40	12	7	3	70	2	17	-	8000	158
405292	LMP.F-80-SST-M8x50-TR	396105	LMP.F-80-A4-M8x50-TR	80	M8	50	12	7	3	70	2	17	-	8000	165
405293	LMP.F-80-SST-M8x63-TR	396108	LMP.F-80-A4-M8x63-TR	80	M8	63	12	7	3	70	2	17	-	8000	182
405296	LMP.F-80-SST-M10x50-TR	396122	LMP.F-80-A4-M10x50-TR	80	M10	50	12	7	3	70	2	17	-	14000	162
405297	LMP.F-80-SST-M10x60-TR	396125	LMP.F-80-A4-M10x60-TR	80	M10	60	12	7	3	70	2	17	-	14000	186
405298	LMP.F-80-SST-M10x80-TR	396128	LMP.F-80-A4-M10x80-TR	80	M10	80	12	7	3	70	2	17	-	14000	208
405299	LMP.F-80-SST-M10x100-TR	396131	LMP.F-80-A4-M10x100-TR	80	M10	100	12	7	3	70	2	17	-	14000	232
405301	LMP.F-80-SST-M12x60-TR	396152	LMP.F-80-A4-M12x60-TR	80	M12	60	12	7	3	70	2	17	-	20000	202
405302	LMP.F-80-SST-M12x80-TR	396155	LMP.F-80-A4-M12x80-TR	80	M12	80	12	7	3	70	2	17	-	20000	222
405303	LMP.F-80-SST-M12x100-TR	396158	LMP.F-80-A4-M12x100-TR	80	M12	100	12	7	3	70	2	17	-	20000	253
405304	LMP.F-80-SST-M12x125-TR	396161	LMP.F-80-A4-M12x125-TR	80	M12	125	12	7	3	70	2	17	-	20000	293
405306	LMP.F-80-SST-M16x75-TR	396182	LMP.F-80-A4-M16x75-TR	80	M16	75	18	7	3	70	2	12	8	20000	283
405307	LMP.F-80-SST-M16x100-TR	396185	LMP.F-80-A4-M16x100-TR	80	M16	100	18	7	3	70	2	12	8	20000	323
405308	LMP.F-80-SST-M16x125-TR	396188	LMP.F-80-A4-M16x125-TR	80	M16	125	18	7	3	70	2	12	8	20000	364
405309	LMP.F-80-SST-M16x150-TR	396191	LMP.F-80-A4-M16x150-TR	80	M16	150	18	7	3	70	2	12	8	20000	404
405310	LMP.F-80-SST-M16x200-TR	396194	LMP.F-80-A4-M16x200-TR	80	M16	200	18	7	3	70	2	12	8	20000	480
405311	LMP.F-80-SST-M20x75-TR	396212	LMP.F-80-A4-M20x75-TR	80	M20	75	19	7	3	70	2	15	10	20000	364
405312	LMP.F-80-SST-M20x100-TR	396215	LMP.F-80-A4-M20x100-TR	80	M20	100	19	7	3	70	2	15	10	20000	404
405313	LMP.F-80-SST-M20x125-TR	396218	LMP.F-80-A4-M20x125-TR	80	M20	125	19	7	3	70	2	15	10	20000	565
405314	LMP.F-80-SST-M20x150-TR	396221	LMP.F-80-A4-M20x150-TR	80	M20	150	19	7	3	70	2	15	10	20000	404
405246	LMP.F-80-SST-M20x200-TR	396224	LMP.F-80-A4-M20x200-TR	80	M20	200	19	7	3	70	2	15	10	20000	480
405316	LMP.F-80-SST-M24x100-TR	396242	LMP.F-80-A4-M24x100-TR	80	M24	100	22	7	3	70	2	19	12	22000	566
405317	LMP.F-80-SST-M24x125-TR	396245	LMP.F-80-A4-M24x125-TR	80	M24	125	22	7	3	70	2	19	12	22000	636
405318	LMP.F-80-SST-M24x150-TR	396248	LMP.F-80-A4-M24x150-TR	80	M24	150	22	7	3	70	2	19	12	22000	707
405319	LMP.F-80-SST-M24x200-TR	396251	LMP.F-80-A4-M24x200-TR	80	M24	200	22	7	3	70	2	19	12	22000	833



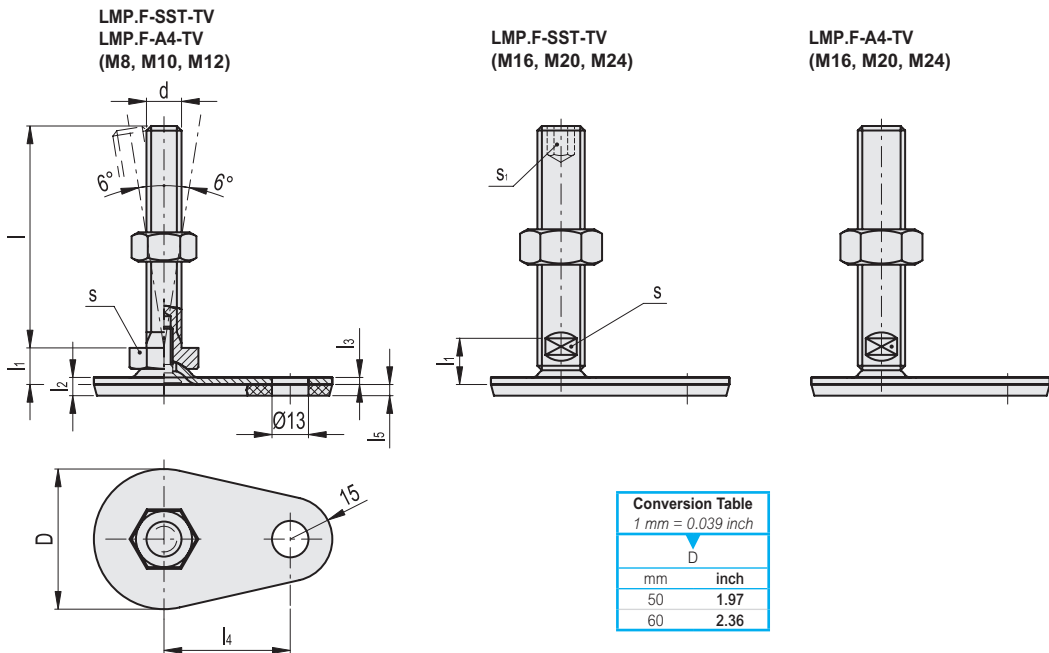


LMP.F-SST-TV (d - l)

LMP.F-A4-TV (d - l)

Code	Description	Code	Description	D	d	l	l1	l2	l3	l4	l5	s	s1#	Max. limit static load [N]	⚖
403783	LMP.F-50-SST-M8x40-TV	395803	LMP.F-50-A4-M8x40-TV	50	M8	40	11	6.5	2.5	45	4	17	-	8000	62
403784	LMP.F-50-SST-M8x50-TV	395806	LMP.F-50-A4-M8x50-TV	50	M8	50	11	6.5	2.5	45	4	17	-	8000	81
403785	LMP.F-50-SST-M8x63-TV	395809	LMP.F-50-A4-M8x63-TV	50	M8	63	11	6.5	2.5	45	4	17	-	8000	91
403786	LMP.F-50-SST-M10x50-TV	395823	LMP.F-50-A4-M10x50-TV	50	M10	50	11	6.5	2.5	45	4	17	-	14000	89
403787	LMP.F-50-SST-M10x60-TV	395826	LMP.F-50-A4-M10x60-TV	50	M10	60	11	6.5	2.5	45	4	17	-	14000	95
403788	LMP.F-50-SST-M10x80-TV	395829	LMP.F-50-A4-M10x80-TV	50	M10	80	11	6.5	2.5	45	4	17	-	14000	101
403789	LMP.F-50-SST-M10x100-TV	395832	LMP.F-50-A4-M10x100-TV	50	M10	100	11	6.5	2.5	45	4	17	-	14000	111
403790	LMP.F-50-SST-M12x60-TV	395853	LMP.F-50-A4-M12x60-TV	50	M12	60	11	6.5	2.5	45	4	17	-	14000	121
403791	LMP.F-50-SST-M12x80-TV	395856	LMP.F-50-A4-M12x80-TV	50	M12	80	11	6.5	2.5	45	4	17	-	14000	131
403792	LMP.F-50-SST-M12x100-TV	395859	LMP.F-50-A4-M12x100-TV	50	M12	100	11	6.5	2.5	45	4	17	-	14000	141
403793	LMP.F-50-SST-M12x125-TV	395862	LMP.F-50-A4-M12x125-TV	50	M12	125	11	6.5	2.5	45	4	17	-	14000	162
403794	LMP.F-50-SST-M16x75-TV	395883	LMP.F-50-A4-M16x75-TV	50	M16	75	17	6.5	2.5	45	4	12	8	14000	180
403795	LMP.F-50-SST-M16x100-TV	395886	LMP.F-50-A4-M16x100-TV	50	M16	100	17	6.5	2.5	45	4	12	8	14000	222
403796	LMP.F-50-SST-M16x125-TV	395889	LMP.F-50-A4-M16x125-TV	50	M16	125	17	6.5	2.5	45	4	12	8	14000	253
403797	LMP.F-50-SST-M16x150-TV	395892	LMP.F-50-A4-M16x150-TV	50	M16	150	17	6.5	2.5	45	4	12	8	14000	283
403798	LMP.F-50-SST-M16x200-TV	395895	LMP.F-50-A4-M16x200-TV	50	M16	200	17	6.5	2.5	45	4	12	8	14000	374
403804	LMP.F-60-SST-M8x40-TV	395913	LMP.F-60-A4-M8x40-TV	60	M8	40	11	7	2.5	50	4.5	17	-	8000	81
403805	LMP.F-60-SST-M8x50-TV	395916	LMP.F-60-A4-M8x50-TV	60	M8	50	11	7	2.5	50	4.5	17	-	8000	90
403806	LMP.F-60-SST-M8x63-TV	395919	LMP.F-60-A4-M8x63-TV	60	M8	63	11	7	2.5	50	4.5	17	-	8000	105
403807	LMP.F-60-SST-M10x50-TV	395933	LMP.F-60-A4-M10x50-TV	60	M10	50	11	7	2.5	50	4.5	17	-	14000	101
403808	LMP.F-60-SST-M10x60-TV	395936	LMP.F-60-A4-M10x60-TV	60	M10	60	11	7	2.5	50	4.5	17	-	14000	111
403809	LMP.F-60-SST-M10x80-TV	395939	LMP.F-60-A4-M10x80-TV	60	M10	80	11	7	2.5	50	4.5	17	-	14000	121
403810	LMP.F-60-SST-M10x100-TV	395942	LMP.F-60-A4-M10x100-TV	60	M10	100	11	7	2.5	50	4.5	17	-	14000	131
403811	LMP.F-60-SST-M12x60-TV	395963	LMP.F-60-A4-M12x60-TV	60	M12	60	11	7	2.5	50	4.5	17	-	16000	126
403812	LMP.F-60-SST-M12x80-TV	395966	LMP.F-60-A4-M12x80-TV	60	M12	80	11	7	2.5	50	4.5	17	-	16000	145
403813	LMP.F-60-SST-M12x100-TV	395969	LMP.F-60-A4-M12x100-TV	60	M12	100	11	7	2.5	50	4.5	17	-	16000	160
403814	LMP.F-60-SST-M12x125-TV	395972	LMP.F-60-A4-M12x125-TV	60	M12	125	11	7	2.5	50	4.5	17	-	16000	182
403815	LMP.F-60-SST-M16x75-TV	395993	LMP.F-60-A4-M16x75-TV	60	M16	75	17	7	2.5	50	4.5	12	8	16000	202
403816	LMP.F-60-SST-M16x100-TV	395996	LMP.F-60-A4-M16x100-TV	60	M16	100	17	7	2.5	50	4.5	12	8	16000	222
403817	LMP.F-60-SST-M16x125-TV	395999	LMP.F-60-A4-M16x125-TV	60	M16	125	17	7	2.5	50	4.5	12	8	16000	263
403818	LMP.F-60-SST-M16x150-TV	396002	LMP.F-60-A4-M16x150-TV	60	M16	150	17	7	2.5	50	4.5	12	8	16000	303
403819	LMP.F-60-SST-M16x200-TV	396005	LMP.F-60-A4-M16x200-TV	60	M16	200	17	7	2.5	50	4.5	12	8	16000	399

only for LMP.F-SST

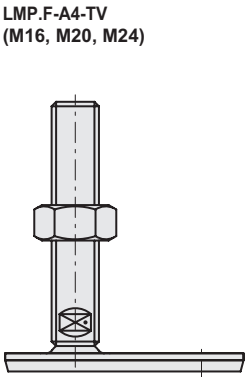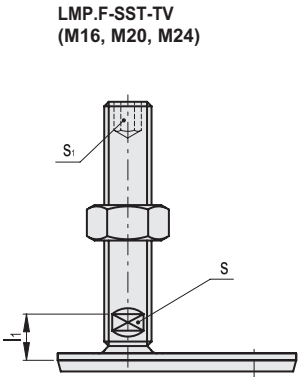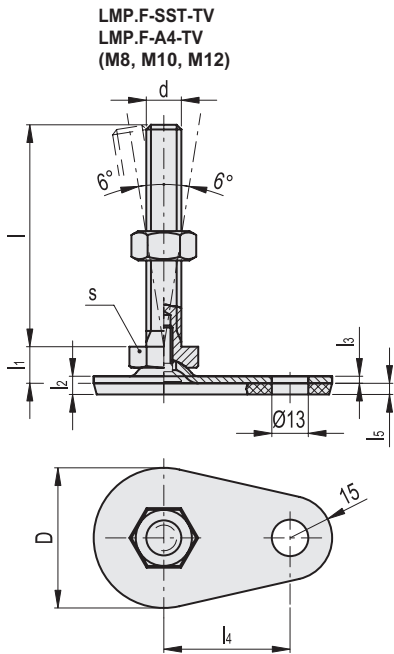

Conversion Table	
1 mm = 0.039 inch	
mm	inch
80	3.15

LMP.F-SST-TV (d - l)

LMP.F-A4-TV (d - l)

INOX STAINLESS STEEL METRIC

Code	Description	Code	Description	D	d	l	l1	l2	l3	l4	l5	s	s1#	Max. limit static load [N]	⚖
403824	LMP.F-80-SST-M8x40-TV	396103	LMP.F-80-A4-M8x40-TV	80	M8	40	12	8	3	70	5	17	-	8000	158
403825	LMP.F-80-SST-M8x50-TV	396106	LMP.F-80-A4-M8x50-TV	80	M8	50	12	8	3	70	5	17	-	8000	165
403826	LMP.F-80-SST-M8x63-TV	396109	LMP.F-80-A4-M8x63-TV	80	M8	63	12	8	3	70	5	17	-	8000	182
403827	LMP.F-80-SST-M10x50-TV	396123	LMP.F-80-A4-M10x50-TV	80	M10	50	12	8	3	70	5	17	-	14000	162
403828	LMP.F-80-SST-M10x60-TV	396126	LMP.F-80-A4-M10x60-TV	80	M10	60	12	8	3	70	5	17	-	14000	186
403829	LMP.F-80-SST-M10x80-TV	396129	LMP.F-80-A4-M10x80-TV	80	M10	80	12	8	3	70	5	17	-	14000	208
403830	LMP.F-80-SST-M10x100-TV	396132	LMP.F-80-A4-M10x100-TV	80	M10	100	12	8	3	70	5	17	-	14000	232
403831	LMP.F-80-SST-M12x60-TV	396153	LMP.F-80-A4-M12x60-TV	80	M12	60	12	8	3	70	5	17	-	20000	202
403832	LMP.F-80-SST-M12x80-TV	396156	LMP.F-80-A4-M12x80-TV	80	M12	80	12	8	3	70	5	17	-	20000	222
403833	LMP.F-80-SST-M12x100-TV	396159	LMP.F-80-A4-M12x100-TV	80	M12	100	12	8	3	70	5	17	-	20000	253
403834	LMP.F-80-SST-M12x125-TV	396162	LMP.F-80-A4-M12x125-TV	80	M12	125	12	8	3	70	5	17	-	20000	293
403835	LMP.F-80-SST-M16x75-TV	396183	LMP.F-80-A4-M16x75-TV	80	M16	75	18	8	3	70	5	12	8	20000	283
403836	LMP.F-80-SST-M16x100-TV	396186	LMP.F-80-A4-M16x100-TV	80	M16	100	18	8	3	70	5	12	8	20000	323
403837	LMP.F-80-SST-M16x125-TV	396189	LMP.F-80-A4-M16x125-TV	80	M16	125	18	8	3	70	5	12	8	20000	364
403838	LMP.F-80-SST-M16x150-TV	396192	LMP.F-80-A4-M16x150-TV	80	M16	150	18	8	3	70	5	12	8	20000	404
403846	LMP.F-80-SST-M16x200-TV	396195	LMP.F-80-A4-M16x200-TV	80	M16	200	18	8	3	70	5	12	8	20000	500
403839	LMP.F-80-SST-M20x75-TV	396213	LMP.F-80-A4-M20x75-TV	80	M20	75	19	8	3	70	5	15	10	20000	364
403840	LMP.F-80-SST-M20x100-TV	396216	LMP.F-80-A4-M20x100-TV	80	M20	100	19	8	3	70	5	15	10	20000	404
403841	LMP.F-80-SST-M20x125-TV	396219	LMP.F-80-A4-M20x125-TV	80	M20	125	19	8	3	70	5	15	10	20000	565
403842	LMP.F-80-SST-M20x150-TV	396222	LMP.F-80-A4-M20x150-TV	80	M20	150	19	8	3	70	5	15	10	20000	404
403848	LMP.F-80-SST-M20x200-TV	396225	LMP.F-80-A4-M20x200-TV	80	M20	200	19	8	3	70	5	15	10	20000	680
403843	LMP.F-80-SST-M24x100-TV	396243	LMP.F-80-A4-M24x100-TV	80	M24	100	22	8	3	70	5	19	12	22000	566
403844	LMP.F-80-SST-M24x125-TV	396246	LMP.F-80-A4-M24x125-TV	80	M24	125	22	8	3	70	5	19	12	22000	636
403845	LMP.F-80-SST-M24x150-TV	396249	LMP.F-80-A4-M24x150-TV	80	M24	150	22	8	3	70	5	19	12	22000	707
403849	LMP.F-80-SST-M24x200-TV	396252	LMP.F-80-A4-M24x200-TV	80	M24	200	22	8	3	70	5	19	12	22000	850

Levelling feet and supports