

MATERIAL

Nickel-plated steel bracket.
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES



Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Clamping screws with ball terminal MM-RG (see page -).

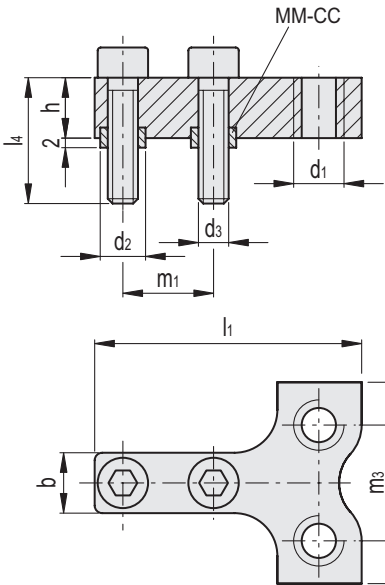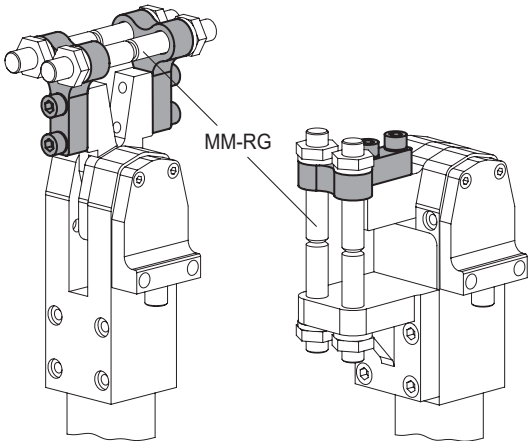

Conversion Table
1 mm = 0.039 inch

b	
mm	inch
10	0.39
12	0.47
16	0.62
18	0.70

Code	Description	b	d1	d2 H8 / h6	d3	h	l1	l3	l4	m1	m3	⚖
MM.26020-NK	MM-A-RG-20-NK	10	M8	7	M5	10	37	30	20	12	17	50
MM.26032-NK	MM-A-RG-32-NK	12	M10	9	M6	12	53	40	25	18	23	98
MM.26040-NK	MM-A-RG-40-NK	16	M12	11	M8	14	63	50	35	22	30	180
MM.26050-NK	MM-A-RG-50-NK	18	M12	13	M10	16	73	60	30	27	40	267