

MATERIAL

Nickel-plated steel bracket.
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES




I-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Clamping screws with ball terminal MM-RG (see page -).

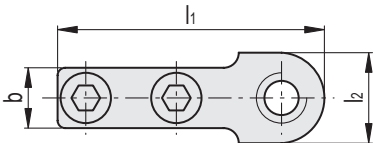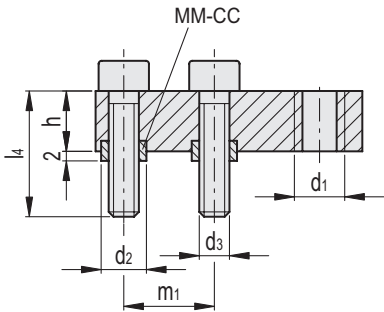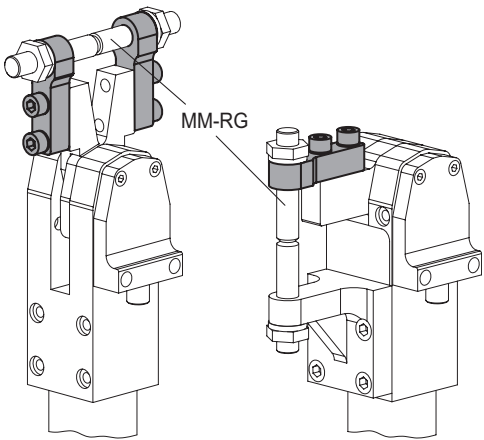

Conversion Table	
1 mm = 0.039 inch	
b	
mm	inch
10	0.39
12	0.47
16	0.62
18	0.70

Code	Description	b	d1	d2 H8 / h6	d3	h	l1	l2	l4	m1	⚖
MM.27020-NK	MM-A-RG1-20-NK	10	M8	7	M5	10	37	13	20	12	36
MM.27032-NK	MM-A-RG1-32-NK	12	M10	9	M6	12	53	17	25	18	70
MM.27040-NK	MM-A-RG1-40-NK	16	M12	11	M8	14	63	20	35	22	141
MM.27050-NK	MM-A-RG1-50-NK	18	M12	13	M10	16	73	20	30	27	189