

MATERIAL

Nickel-plated steel bracket.  
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES




Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Jaw blocks MM-SC (see page -).

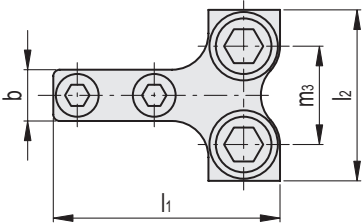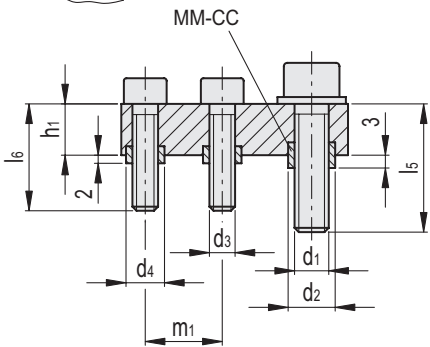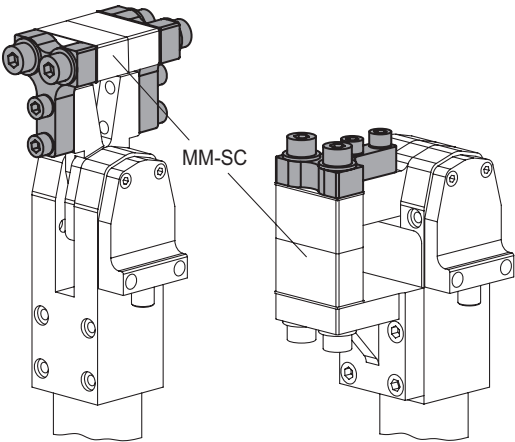

| Conversion Table  |      |
|-------------------|------|
| 1 mm = 0.039 inch |      |
| b                 |      |
| mm                | inch |
| 10                | 0.39 |
| 12                | 0.47 |
| 16                | 0.62 |
| 18                | 0.70 |

| Code        | Description   | b  | d1  | d2 H8 / h6 | d3  | d4 H8 / h6 | h1 | l1 | l2 | l5 | l6 | m1 | m3 | Δ   |
|-------------|---------------|----|-----|------------|-----|------------|----|----|----|----|----|----|----|-----|
| MM.21020-NK | MM-A-SC-20-NK | 10 | M6  | 9          | M5  | 7          | 10 | 37 | 30 | 20 | 20 | 12 | 17 | 30  |
| MM.21032-NK | MM-A-SC-32-NK | 12 | M8  | 11         | M6  | 9          | 12 | 53 | 40 | 25 | 25 | 18 | 23 | 138 |
| MM.21040-NK | MM-A-SC-40-NK | 16 | M10 | 13         | M8  | 11         | 14 | 63 | 50 | 30 | 35 | 22 | 30 | 248 |
| MM.21050-NK | MM-A-SC-50-NK | 18 | M10 | 13         | M10 | 13         | 16 | 73 | 60 | 40 | 30 | 27 | 40 | 335 |