

MATERIAL

Nickel-plated steel bracket.
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES




I-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Jaw blocks MM-SC (see page -).

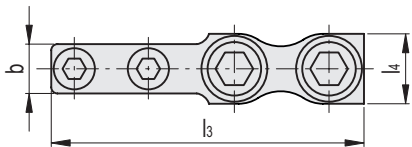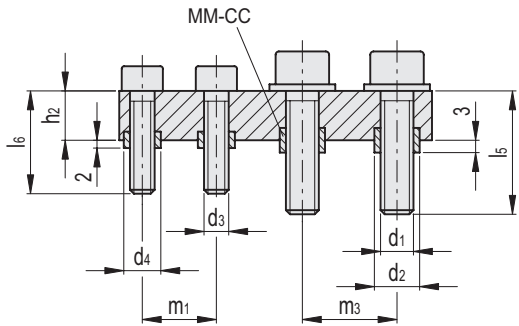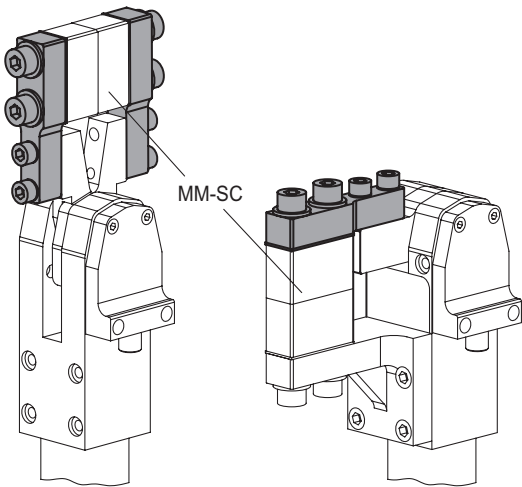

Conversion Table
1 mm = 0.039 inch

b	
mm	inch
10	0.39
12	0.47
16	0.62
18	0.70

METRIC

Code	Description	b	d1	d2 H8 / h6	d3	d4 H8 / h6	h2	l3	l4	l5	l6	m1	m3	Δ
MM.35020-NK	MM-A-SCL-20-NK	10	M6	9	M5	7	10	54	13	20	20	12	17	62
MM.35032-NK	MM-A-SCL-32-NK	12	M8	11	M6	9	14	76	17	25	25	18	23	142
MM.35040-NK	MM-A-SCL-40-NK	16	M10	13	M8	11	16	93	20	30	35	22	30	273
MM.35050-NK	MM-A-SCL-50-NK	18	M10	13	M10	13	18	113	20	40	30	27	40	379