



MATERIAL





Polyurethane (PUR) connector, black colour, thermoplastic (TPU) polyurethane cable, orange colour and nickel-plated brass nut.

FEATURES

Connector with housing and contact holder 4 pole M12x1.
IP67 protection class and cables compatible with aggressive environments.

COMPATIBILITY

Proximity switch MM-SI (see page -).

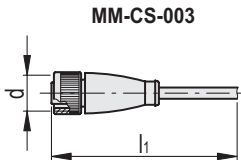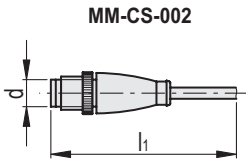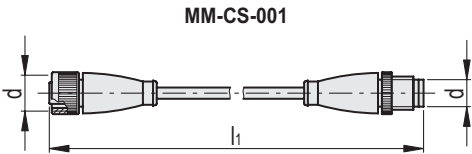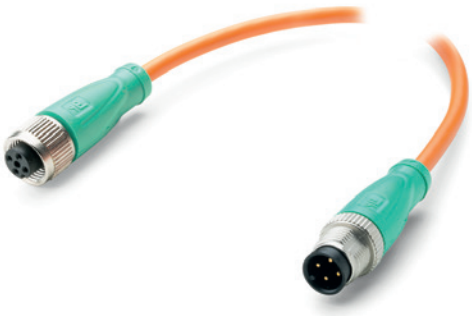

Conversion Table	
1 mm = 0.039 inch	
l1	
mm	inch
600	23.62
1000	39.37
2000	78.74

Code	Description	d	l1	⚖
MM.22106	MM-CS-001/600	M12 x 1	600	48
MM.22110	MM-CS-001/1000	M12 x 1	1000	60
MM.22120	MM-CS-001/2000	M12 x 1	2000	81
MM.22220	MM-CS-002/2000	M12 x 1	2000	64
MM.22320	MM-CS-003/2000	M12 x 1	2000	64