

MATERIAL

Nickel-plated steel bracket.
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES AND APPLICATIONS




The brackets are compatible with the pneumatic fastening clamps MM-BI-NK (see page -).
These brackets are used in applications where it is necessary to effectively block a metal sheet.

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Clamping screws with ball terminal MM-RG (see page -).

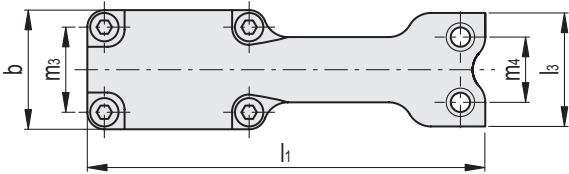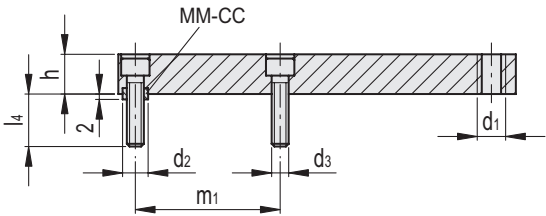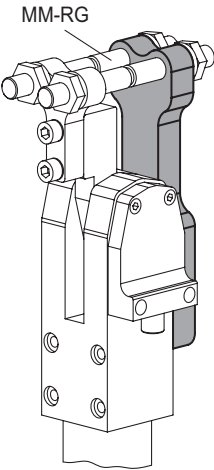

Conversion Table	
1 mm = 0.039 inch	
b	
mm	inch
32	1.25
42	1.64
52	2.03
62	2.42

Code	Description	b	d1	d2 H8 / h6	d3	h	l1	l3	l4	m1	m3	m4	⚖️
MM.42020-NK	MM-FI-RG-20-NK	32	M8	7	M5	10	98.5	30	8	34	22	17	174
MM.42032-NK	MM-FI-RG-32-NK	42	M10	9	M6	14	140	40	8.5	51	30	23	436
MM.42040-NK	MM-FI-RG-40-NK	52	M12	11	M8	16	168	50	12.5	62	37	30	851
MM.42050-NK	MM-FI-RG-50-NK	62	M12	13	M10	18	192.5	60	12.5	71.5	44	40	949