

MATERIAL

Nickel-plated steel bracket.
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES




The brackets are compatible with the pneumatic fastening clamps MM-BI-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Jaw blocks MM-SC (see page -).

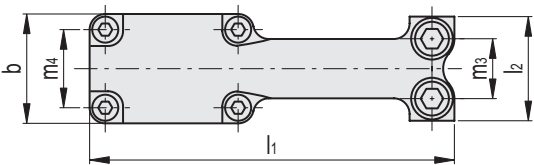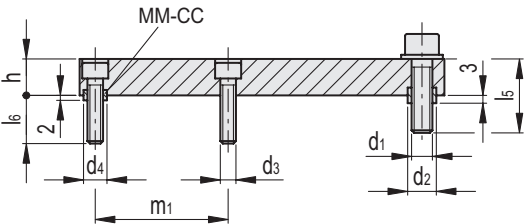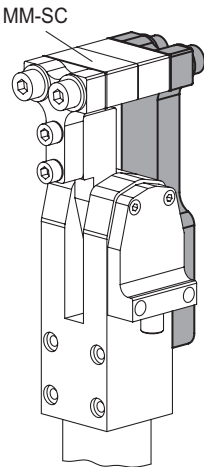

Conversion Table	
1 mm = 0.039 inch	
b	
mm	inch
32	1.25
42	1.64
52	2.03
62	2.42

METRIC

Code	Description	b	d1	d2 H8 / h6	d3	d4 H8 / h6	h	l1	l2	l5	l6	m1	m3	m4	Δ
MM.37020-NK	MM-FI-SC-20-NK	32	M6	9	M5	7	10	98.5	30	20	8	34	17	22	197
MM.37032-NK	MM-FI-SC-32-NK	42	M8	11	M6	9	14	140	40	25	8.5	51	23	30	529
MM.37040-NK	MM-FI-SC-40-NK	52	M10	13	M8	11	16	168	50	30	12.5	62	30	37	925
MM.37050-NK	MM-FI-SC-50-NK	62	M10	13	M10	13	18	192.5	60	30	12.5	71.5	40	44	1021