

MATERIAL

Nickel-plated steel bracket.
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES



The brackets are compatible with the pneumatic fastening clamps MM-BI-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Jaw blocks MM-SC (see page -).

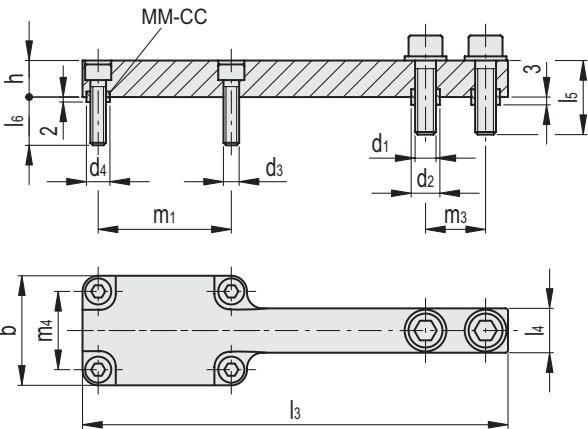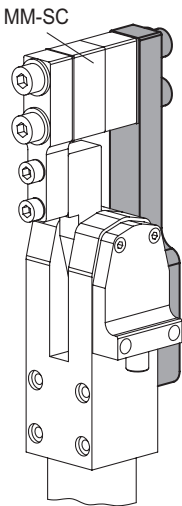

Conversion Table
1 mm = 0.039 inch

b	mm	inch
32	1.25	
42	1.64	
52	2.03	
62	2.42	

METRIC

Code	Description	b	d1	d2 H8 / h6	d3	d4 H8 / h6	h	l3	l4	l5	l6	m1	m3	m4	Δ
MM.49020-NK	MM-FI-SCL-20-NK	32	M6	9	M5	7	10	115.5	15	20	8	34	17	22	197
MM.49032-NK	MM-FI-SCL-32-NK	42	M8	11	M6	9	14	163	19	25	8.5	51	23	30	512
MM.49040-NK	MM-FI-SCL-40-NK	52	M10	13	M8	11	16	198	20	30	12.5	62	30	37	847
MM.49050-NK	MM-FI-SCL-50-NK	62	M10	13	M10	13	18	232.5	20	30	12.5	71.5	40	44	1047