

MATERIAL

Nickel-plated steel bracket.
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES




The brackets are compatible with the pneumatic fastening clamps MM-BL-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Jaw blocks MM-SC (see page -).

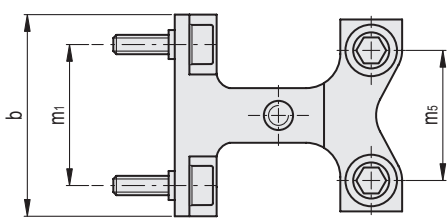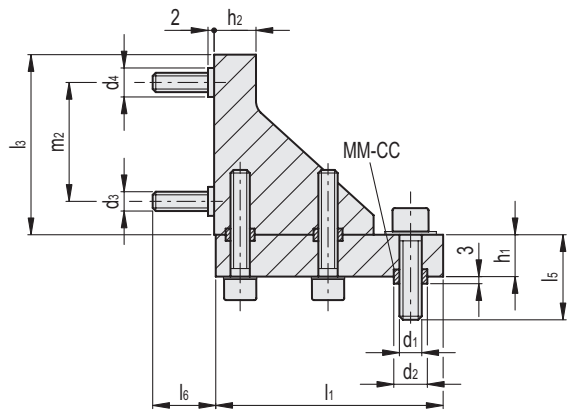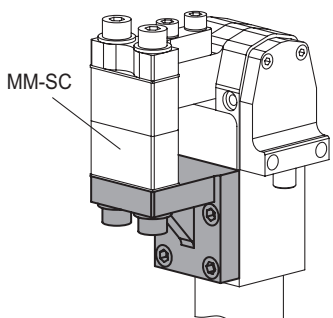

Conversion Table	
1 mm = 0.039 inch	
b	
mm	inch
32	1.25
42	1.64
52	2.03
62	2.42

Code	Description	b	d1	d2 H8 / h6	d3	d4 H8 / h6	h1	h2	l1	l3	l5	l6	m1	m2	m5	Δ
MM.40020-NK	MM-FL-SC-20-NK	32	M6	9	M5	7	10	10	38	37	20	7.5	22	17	17	166
MM.40032-NK	MM-FL-SC-32-NK	42	M8	11	M6	9	12	12	54.5	48.5	25	10	30	25	23	372
MM.40040-NK	MM-FL-SC-40-NK	52	M10	13	M8	11	14	14	63	61	30	13.5	37	30	30	668
MM.40050-NK	MM-FL-SC-50-NK	62	M10	13	M10	13	16	16	73.5	83.5	30	13.5	44	47	40	851