

MATERIAL

Nickel-plated steel bracket.
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES




The brackets are compatible with the pneumatic fastening clamps MM-BL-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Jaw blocks MM-SC (see page -).

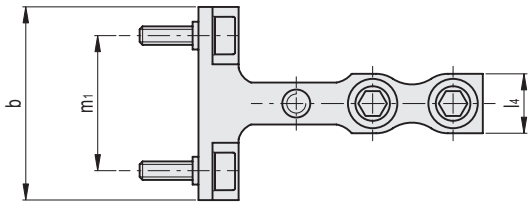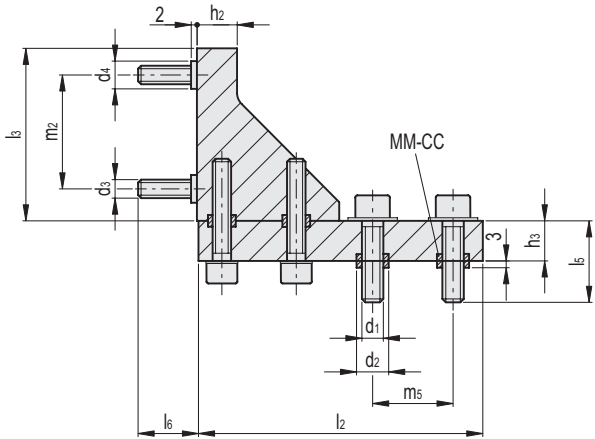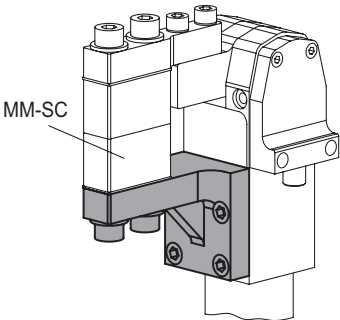

Conversion Table	
1 mm = 0.039 inch	
mm	inch
32	1.25
42	1.64
52	2.03
62	2.42

Code	Description	b	d1	d2 H8 / h6	d3	d4 H8 / h6	h2	h3	l2	l3	l4	l5	l6	m1	m2	m5	Δ
MM.52020-NK	MM-FL-SCL-20-NK	32	M6	9	M5	7	10	10	55	37	13	18.5	7.5	22	17	17	156
MM.52032-NK	MM-FL-SCL-32-NK	42	M8	11	M6	9	12	14	77.5	50.5	17	23.5	10	30	25	23	362
MM.52040-NK	MM-FL-SCL-40-NK	52	M10	13	M8	11	14	14	93	61	20	28	13.5	37	30	30	620
MM.52050-NK	MM-FL-SCL-50-NK	62	M10	13	M10	13	16	18	113.5	85.5	20	29	13.5	44	47	40	978