



MATERIAL




Black anodised aluminium.

FEATURES

The rear protections prevent any processing residues or external bodies from penetrating inside the pneumatic fastening clamps MM-BL-NK (see page -).

SPECIAL EXECUTION ON REQUEST

Rear protection with Teflon coating.

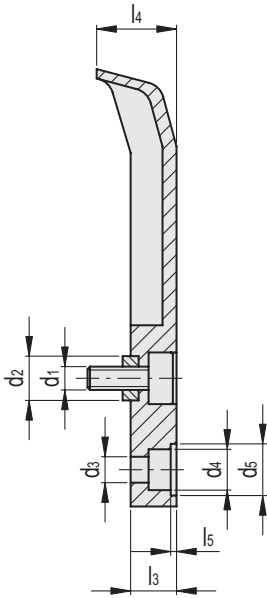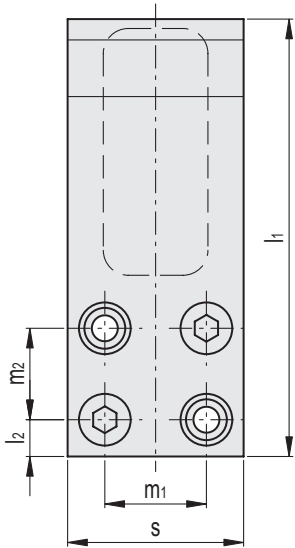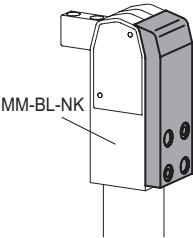

Conversion Table			
1 mm = 0.039 inch			
l1		s	
mm	inch	mm	inch
76	2.99	32	1.26
109	4.29	42	1.65
131	5.16	52	2.05
162	6.38	62	2.44

Code	Description	d1	d2 H8 / h6	d3	d4	d5	l1	l2	l3	l4	l5	s	m1	m2	⚖
MM.36020	MM-PTA-20	M5	7	5.5	7	9	76	5	10	15.5	2.1	32	22	17	56
MM.36032	MM-PTA-32	M6	9	6.5	9	11	109	6.5	12	20	2.1	42	30	25	104
MM.36040	MM-PTA-40	M8	11	8.5	11	13	131	7.5	14	23	2.1	52	37	30	230
MM.36050	MM-PTA-50	M10	13	10.5	13	16	162	9	16	27	3.1	62	44	47	639