

MATERIAL



Black-oxide steel screw and nut.
Zinc-plated steel washers.
Hardened steel knurled flat-faced ball, non-reversible.

FEATURES

The clamping screws are suitable for clamping workpieces.
They are compatible with arms and brackets which are themselves compatible with the pneumatic fastening clamps MM-BL (see page -), MM-BI (see page -) or MM-BC (see page -).

SPECIAL EXECUTIONS ON REQUEST

- Acetal resin based (Delrin) technopolymer screws with flat-faced ball.
- Screws with thrust pad.

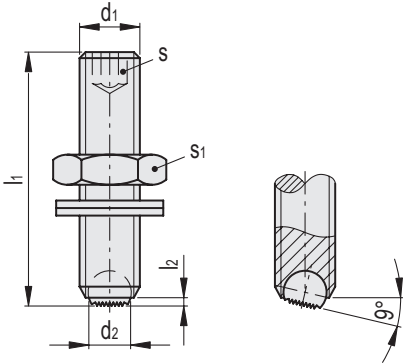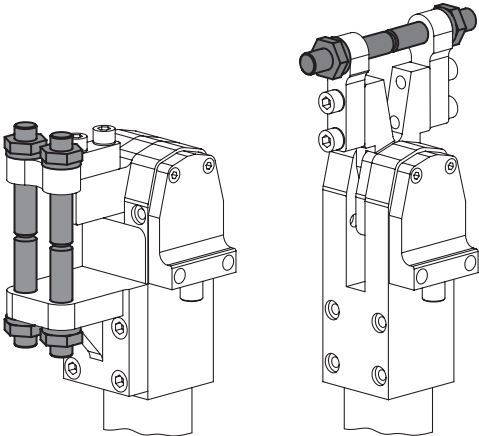

Conversion Table	
1 mm = 0.039 inch	
l1	
mm	inch
30	1.18
40	1.57
50	1.97
60	2.36

Code	Description	d1	d2	l1	l2	s	s1	⚖
MM.25203	MM-RG-20-30	M8	4.8	30	0.5	4	13	12
MM.25020	MM-RG-20	M8	4.8	40	0.5	4	13	16
MM.25032	MM-RG-32	M10	6.4	50	0.7	5	17	25
MM.25040	MM-RG-40	M12	8.2	50	0.9	6	19	30
MM.25050	MM-RG-50	M12	8.2	60	0.9	6	19	36