

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18
- 19

**MATERIAL**


AISI 304 stainless steel.

**STANDARD EXECUTIONS**

- **MPG-P (d)**: with threaded hole.
- **MPG-P (d1)**: with threaded pin.



**FEATURES AND APPLICATIONS**

MPG-P fixing pins are generally used in combination with guide rail clamps MPG-R-AZ, MPG-R-SST, MPG-S or with profiles used PRA-GLB, PRB-GLB to fix the side guides to the guide rail brackets. SPR. e SPR.V.

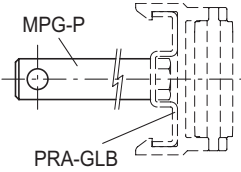

Levelling feet and supports

| Conversion Table  |      |
|-------------------|------|
| 1 mm = 0,039 inch |      |
| D                 |      |
| mm                | inch |
| 12                | 0.47 |
| 14                | 0.55 |
| 16                | 0.62 |

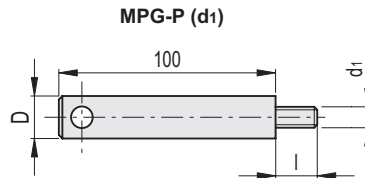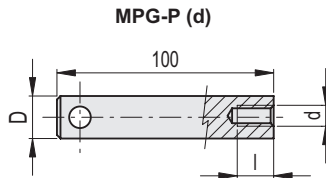

**INOX** STAINLESS STEEL **METRIC**

**MPG-P (d)**

| Code   | Description | d  | D  | l  | △   |
|--------|-------------|----|----|----|-----|
| 419690 | MPG-P12-M8  | M8 | 12 | 20 | 78  |
| 419691 | MPG-P14-M8  | M8 | 14 | 20 | 110 |
| 419692 | MPG-P16-M8  | M8 | 16 | 20 | 130 |

**INOX** STAINLESS STEEL **METRIC**

**MPG-P (d1)**

| Code   | Description    | d1  | D  | l  | △   |
|--------|----------------|-----|----|----|-----|
| 419511 | MPG-P12-M10x17 | M10 | 12 | 17 | 94  |
| 419512 | MPG-P14-M10x17 | M10 | 14 | 17 | 126 |
| 419513 | MPG-P16-M10x17 | M10 | 16 | 17 | 162 |