

# MTP. | Latch clamps, heavy-duty series

Steel



- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18

## MATERIAL

Black coated weldable steel.

## SHANK

Ground and hardened steel.

## PULLING HOOK

Zinc-plated steel.

## OSCILLATING PIN AND NUTS


 
Zinc-plated steel.

## FEATURES AND APPLICATIONS

All articulated joints are lubricated with special grease.

MTP clamps ensure tight closing of any cover; they are suitable for use with high resistant torque thanks to high mechanical resistance of materials.

The position of the pulling hook can be adjusted in length according to the specific applications.

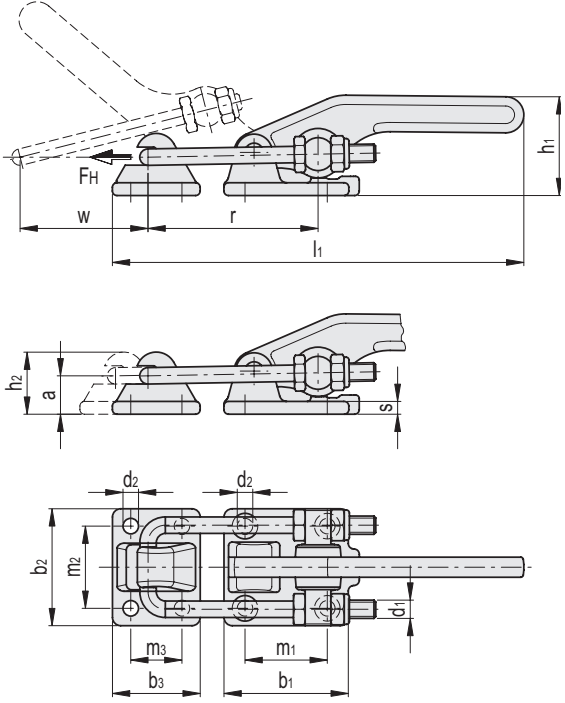

METRIC

Code	Description	a	b1	b2	b3	d1	d2	h1	h2	l1	m1	m2	m3	r	s	Stroke w	FH [N]*	
GG.AL518	MTP.1700-T2	21	68	64	48	M10	8.5	55	34	226	45	45	28	94+106	7	54+58	17000	1085
GG.AL522	MTP.4000-T2	27	85	80	60	M12	10.5	68	42	282	57	57	35	102+124	9	62+65	40000	2070

\* Holding force.



Models all rights reserved in accordance with the law. Always mention the source when reproducing our drawings and photos.

