

MATERIAL


Polyamide based (PA) technopolymer, natural colour.

FEATURES AND APPLICATIONS

The screw is similar in shape and size to that specified in DIN 84 or ISO 1207.

It is made entirely from insulating material that is resistant to corrosion and chemicals. It is suitable for use on metal or timber structures, in industry, aeronautics, electronics, and in all cases where weight reduction is required.

The product is tested for mechanical and dimensional performance. Slight colour variations are perfectly normal and do not affect the quality of the product.

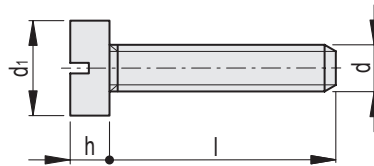

Code	Description	d	d1	l	h	Maximum tightening torque [Nm]	⚖
504701	SRD.84-M4X10-TP-N	M4	7	10	2.5	0.15	1
504702	SRD.84-M4X16-TP-N	M4	7	16	2.5	0.15	1
504703	SRD.84-M4X20-TP-N	M4	7	20	2.5	0.15	1
504704	SRD.84-M4X25-TP-N	M4	7	25	2.5	0.15	1
504711	SRD.84-M5X16-TP-N	M5	7	16	3.5	0.25	1
504712	SRD.84-M5X20-TP-N	M5	8.5	20	3.5	0.25	1
504713	SRD.84-M5X25-TP-N	M5	8.5	25	3.5	0.25	1
504714	SRD.84-M5X30-TP-N	M5	8.5	30	3.5	0.25	1
504715	SRD.84-M5X40-TP-N	M5	8.5	40	3.5	0.25	1.5
504716	SRD.84-M5X50-TP-N	M5	8.5	50	3.5	0.25	1.5
504721	SRD.84-M6X16-TP-N	M6	10	16	4	0.5	1
504722	SRD.84-M6X20-TP-N	M6	10	20	4	0.5	1
504723	SRD.84-M6X25-TP-N	M6	10	25	4	0.5	1.5
504724	SRD.84-M6X30-TP-N	M6	10	30	4	0.5	2
504725	SRD.84-M6X40-TP-N	M6	10	40	4	0.5	2.5
504726	SRD.84-M6X50-TP-N	M6	10	50	4	0.5	3
504731	SRD.84-M8X20-TP-N	M8	13	20	5	1.9	1.5
504732	SRD.84-M8X25-TP-N	M8	13	25	5	1.9	2.5
504733	SRD.84-M8X30-TP-N	M8	13	30	5	1.9	3
504734	SRD.84-M8X40-TP-N	M8	13	40	5	1.9	4
504735	SRD.84-M8X50-TP-N	M8	13	50	5	1.9	5
504741	SRD.84-M10X20-TP-N	M10	15	20	6	3	4
504742	SRD.84-M10X25-TP-N	M10	15	25	6	3	4.5
504743	SRD.84-M10X30-TP-N	M10	15	30	6	3	5
504744	SRD.84-M10X40-TP-N	M10	15	40	6	3	6.5
504745	SRD.84-M10X50-TP-N	M10	15	50	6	3	8
504746	SRD.84-M10X60-TP-N	M10	15	60	6	3	9.5
504751	SRD.84-M12X20-TP-N	M12	18	20	7	4.7	6
504752	SRD.84-M12X30-TP-N	M12	18	30	7	4.7	8.5
504753	SRD.84-M12X40-TP-N	M12	18	40	7	4.7	10
504754	SRD.84-M12X50-TP-N	M12	18	50	7	4.7	12.5
504755	SRD.84-M12X60-TP-N	M12	18	60	7	4.7	14
504756	SRD.84-M12X80-TP-N	M12	18	80	7	4.7	18.5