

CONNECTOR


Polyamide based (PA) technopolymer, black colour, matte finish.

STANDARD EXECUTIONS

- **2A-2W**: bidimensional two-way connector.
- **3A-3W**: tridimensional three-way connector.


FEATURES AND APPLICATIONS

Suitable for creating structures composed by square profiles. The assembly can be performed simply by positioning the connector, forcing it, inside the profile, with no need of screws or other fasteners.

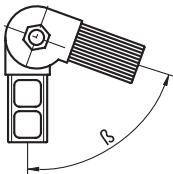


Conversion Table	
1 mm = 0,039 inch	
L	
mm	inch
20	0,79
25	0,98

2A-2W

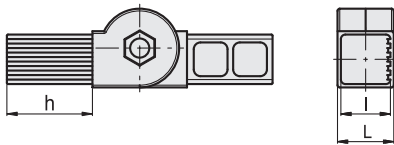

3A-3W

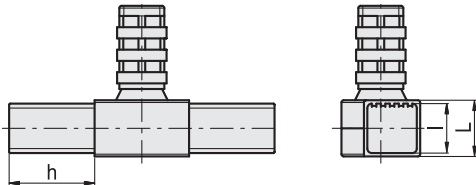

METRIC

Code	Description	L	h	l	β min-max	External tube dimensions	Internal tube dimensions	Tube thickness	⚖
430003	STC.20-2A-2W-A-C9	20	35	17+/-0.15	0 ÷ 190	20	17	1.5	54
430053	STC.25-2A-2W-A-C9	25	38	22+/-0.15	45 ÷ 195	25	22	1.5	64
430103	STC.25-3A-3W-A-C9	25	38	22+/-0.15	45 ÷ 195	25	22	1.5	85